


USK tube connectors, plastic

with high degree of protection

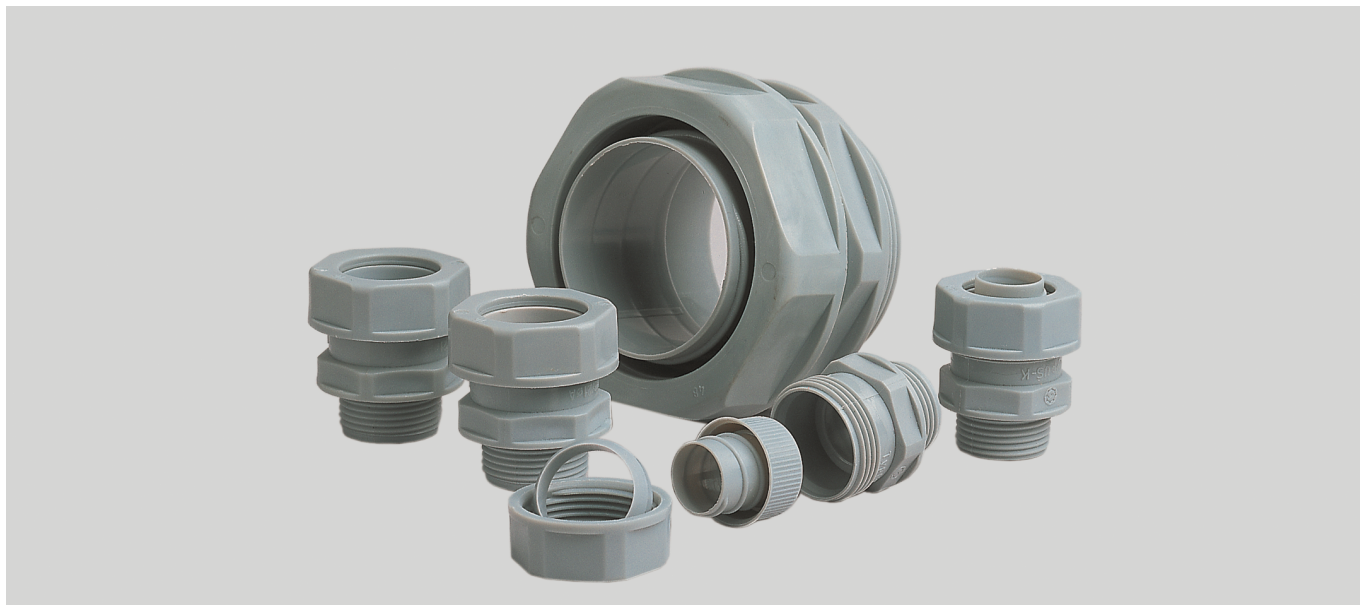

USK

Tube gland for type S, S-PU and K protection tubes.

Material

Polypropylene

Technical data

Protection class: IP 65

Temperature range: -10°C up to +110°C

Application

- Plant and machine construction
- Automation technology
- Installation technology
- Control cabinet construction

metric thread

Part no. grey	Size Metric	Tube outer Ø mm	Thread length mm	Unit	Net EUR/100 items at a purchase of		
					up to 100	101 - 500	501 - 1000
97594	M10 x 1,0	10,0	10,0	50	o. r.	o. r.	o. r.
97595	M12 x 1,5	14,0	12,0	50	o. r.	o. r.	o. r.
97596	M16 x 1,5	17,0	12,0	50	o. r.	o. r.	o. r.
97597	M20 x 1,5	21,0	13,0	50	o. r.	o. r.	o. r.
97598	M25 x 1,5	27,0	13,0	25	o. r.	o. r.	o. r.
97599	M32 x 1,5	36,0	15,0	25	o. r.	o. r.	o. r.
97600	M40 x 1,5	45,0	15,0	25	o. r.	o. r.	o. r.
97601	M50 x 1,5	56,0	16,0	10	o. r.	o. r.	o. r.

metric thread - small package

Part no. grey	Size Metric	Tube outer Ø mm	Thread length mm	Unit	Net EUR/100 items at a purchase of		
					up to 100	101 - 500	501 - 1000
93460	M10 x 1,0	10,0	10,0	10	o. r.	o. r.	o. r.
93461	M12 x 1,5	14,0	12,0	10	o. r.	o. r.	o. r.
93462	M16 x 1,5	17,0	12,0	10	o. r.	o. r.	o. r.
93463	M20 x 1,5	21,0	13,0	10	o. r.	o. r.	o. r.
93464	M25 x 1,5	27,0	13,0	10	o. r.	o. r.	o. r.
93465	M32 x 1,5	36,0	15,0	2	o. r.	o. r.	o. r.
93466	M40 x 1,5	45,0	15,0	2	o. r.	o. r.	o. r.
93467	M50 x 1,5	56,0	16,0	2	o. r.	o. r.	o. r.

Continuation ►

USK tube connectors, plastic

with high degree of protection

PG thread

Part no. grey	Size PG	Tube outer Ø mm	Thread length mm	Unit	Net EUR/ 100 items at a purchase of		
					up to 100	101 - 500	501 - 1000
90664	7	10,0	10,0	50	o. r.	o. r.	o. r.
90665	9	14,0	10,0	50	o. r.	o. r.	o. r.
90666	11	17,0	10,0	50	o. r.	o. r.	o. r.
90667	13,5	19,0	10,0	50	o. r.	o. r.	o. r.
90668	16	21,0	11,0	50	o. r.	o. r.	o. r.
90669	21	27,0	11,0	25	o. r.	o. r.	o. r.
90670	29	36,0	12,0	25	o. r.	o. r.	o. r.
90671	36	45,0	12,0	25	o. r.	o. r.	o. r.
90673	48	56,0	15,0	10	o. r.	o. r.	o. r.

PG thread - small package

Part no. grey	Size PG	Tube outer Ø mm	Thread length mm	Unit	Net EUR/ 100 items at a purchase of		
					up to 100	101 - 500	501 - 1000
93450	7	10,0	10,0	10	o. r.	o. r.	o. r.
93451	9	14,0	10,0	10	o. r.	o. r.	o. r.
93452	11	17,0	10,0	10	o. r.	o. r.	o. r.
93453	13,5	19,0	10,0	10	o. r.	o. r.	o. r.
93454	16	21,0	11,0	10	o. r.	o. r.	o. r.
93455	21	27,0	11,0	10	o. r.	o. r.	o. r.
93456	29	36,0	12,0	2	o. r.	o. r.	o. r.
93457	36	45,0	12,0	2	o. r.	o. r.	o. r.
93458	48	56,0	15,0	2	o. r.	o. r.	o. r.

Dimensions and specifications may be changed without prior notice.

o. r. = on request