


Car Alarm with charging function TX-100

Monitoring of vehicle interiors with PIR motion detection sensor

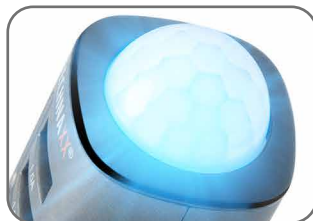

12–24V aufladbarer Autoalarm /
12–24V rechargeable Car Alarm



450mAh Akku /
450mAh Battery



110dB Alarmsirene /
110dB Alarm Siren



Fernbedienung /
Remote Control



Standby-Zeit 6 Tage /
Standby-Time 6 Days



2 USB-Ladeanschlüsse /
2 USB Charging Ports



Alarmauslösung bei Bewegungserkennung /
Alarm Triggering at Motion Detection

- 12–24V rechargeable car alarm for the cigarette lighter socket
- Automatic alarm triggering at motion detection
- Built-in 450mAh battery for ~6 days standby time
- Built-in alarm siren with 110dB
- 2 USB charging ports with 5V/1A output power each
- Remote control to activate/deactivate the alarm
- LED status indicator

Technical Specifications:

- Detecting range: car interior, 120° cone angle
- Distance IR remote control ~8m (open areas)
- Alarm time 2 minutes maximum
- Built-in rechargeable 450mAh lithium polymer battery 4.2V
- Charging time ~3–4 hours / Standby ~6 days
- Input voltage DC 12–24V (cigarette lighter socket)
- Charging current 65mA / Operating current 26mA
- Over current protection 2.8A & Short circuit protection
- Transmission frequency 433,92 MHz / type: ASK
- Maximum radiated transmission power 20mW
- Weight/Dimensions car alarm: 44g / (L) 3.2 x (W) 3.2 x (H) 11.5cm
- Weight/Dimensions remote control: 10g / (L) 5.3 x (W) 3.1 x (H) 1.0cm

Package Contents:

- Car Alarm with charging function TX-100
- Remote control (with button cell battery CR2032 3V)
- User Manual



Article-No. 4743

