
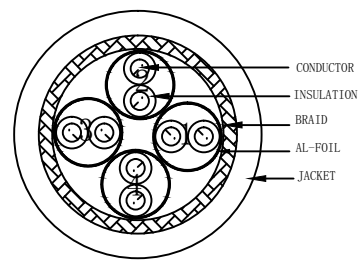


PIN OUT

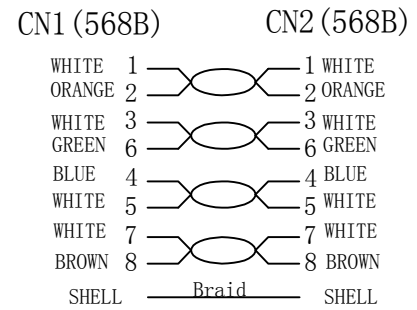

NOTE:

1. ELECTRICAL TEST:100% OPEN SHORT, MISS WIRE TEST
2. TEST LIMIT:ISO11801 Channel Class E
3. Working temperature:-10°C ~ + 60°C
4. Plug Contacts durability:750 cycles min
5. RoHS2.0 AND REACH compliant
6. Spray WORD:
CAT. 6 S/FTP 27AWG 250MHz LSZH PATCH CORD ISO/IEC 11801 & EN50173 & TIA/EIA 568 C. 2

MATERIAL LIST

③	CABLE	CAT. 6 S/FTP 27AWG (BC*1P+AL-FOIL)*4+BRAID AL-MG JACKET:LSZH OD:5.8±0.2mm	1	
②	Over mold	PVC 75A	2	
①	Plug	RJ45 8P8C' S SHIELDED , THE SHELL PLATED NICKEL, PIN GOLD PLATED 3u" RED/TRANSPARENT	2	
NO.	PARTS NAME	SPECIFICATION STANDARD	QT' Y	REMARK
		NEW	2020-10-29	A
BY	CHK	REVISION RECORD MODIFICATIONS	DATE	REV.

Renkforce					
CUSTOMER NO.	Renkforce	ITEM NO.			
PRODUCT NAME	Cat. 6 S/FTP Round Patch cord 27AWG	UNO ITEM NO.	216333	UNIT	MM
DRAWNBY	CHECKBY	APPOBY	DATE		
ARVIN	ALVAN		2020-10-29		

Color:Blue (Pantone 647C)	
BN NO.	LENGTH
1650896	150+10/-0MM
1650894	250+10/-0MM
1650903	500+20/-0MM
1650908	1000+20/-0MM
1650898	3000+50/-0MM
1650907	5000+100/-0MM
1650899	10000+200/-0MM
1650901	15000+300/-0MM
1650914	20000+300/-0MM
1650911	30000+300/-0MM

Renkforce						
CUSTOMER NO.	Renkforce		ITEM NO.			
PRODUCT NAME	Cat. 6 S/FTP Round Patch cord 27AWG		UNO ITEM NO.	216333	UNIT	MM
DRAWNBY		CHECKBY	APPOBY	DATE		
ARVIN		ALVAN		2020-10-29		

		NEW	2020-10-29	A	
BY	CHK	REVISION RECORD MODIFICATIONS	DATE	REV.	