

Note:
 ROHS 2.0 & REACH Compliant
 Test:
 Grade Designation: Each to Reference

| TYPE | MULTI-MODE |
|-----------------|------------------------|
| Insertion Loss | ≤0.3dB (IEC 61300-3-4) |
| Return Loss | ≥30dB (IEC 61300-3-6) |
| Test Wavelength | 850nm |

1pcs/PE bag+test report

MATERIAL LIST:

| | | | |
|-----|--|--------|--------|
| ⑧ | Ring 1、2 | 4pcs | |
| ⑦ | Black Heat Shrink Tube | 2pcs | |
| ⑥ | LC Duplex Clip Erika violet | 2pcs | |
| ⑤ | LC Dust Cap White | 4pcs | |
| ④ | LC Duplex Connector Erika violet | 4pcs | |
| ③ | LC 2.0 white Boot | 4pcs | |
| ② | LC/UPC MM Ferrule ceramic | 4pcs | |
| ① | Fiber Optical Cable Duplex 50/125 OM4 ϕ 2.0mm LSZH Erika violet | L+0.1m | |
| NO. | SPECIFICATION STANDARD | QT' Y | REMARK |

| Renkforce | | | | | |
|--------------|--|----------|---------------|---------|----------|
| CUSTOMER | | ITEM NO. | see the chart | | |
| PRODUCT NAME | LC-LC Duplex Patch Cord OM4 2.0 Erika violet | | | UNIT | MM |
| BY | CHK | DATE | REV. | DRAWNBY | CHECKBY |
| | | 2021-1-7 | A | Kerry | Kerry |
| | | | | APPOBY | DATE |
| | | | | | 2021-1-7 |

| | | | | |
|----|-----|-------------------------------|----------|------|
| | | NEW | 2021-1-7 | A |
| BY | CHK | REVISION RECORD MODIFICATIONS | DATE | REV. |

Test report for example:

| TEST REPORT | | | | | |
|-----------------------------------|--|--|---------------|---------------|---------------|
| Batch No. | | Attention: Please clean the fiber surfaces! Achtung: Bitte reinigen die Steckermittelfächer | | | |
| PO NO. | | | | | |
| ITEM Number | | | | | |
| Description | | | | | |
| Notes | | | | | |
| Min. bending radius (mm) | Static: 10*D Dynamic: 20*D | D: Cable diameter | | | |
| TEST VALUES | | | | | |
| Standard (Each to Reference) | Allow Loss $\lambda = 850\text{nm}$ | CHANNEL 1 | | CHANNEL 2 | |
| | | LC Conn. 1 | LC Conn. 2 | LC Conn. 1 | LC Conn. 2 |
| Insertion Loss (IEC 61300-3-4) | $< 0.30\text{dB}$ | dB | dB | dB | dB |
| Return Loss (IEC 61300-3-6) | $\text{UPC} > 30\text{dB}$ | dB | dB | dB | dB |
| RESULT | | OK | | | |

PACKING DRAW

Test report

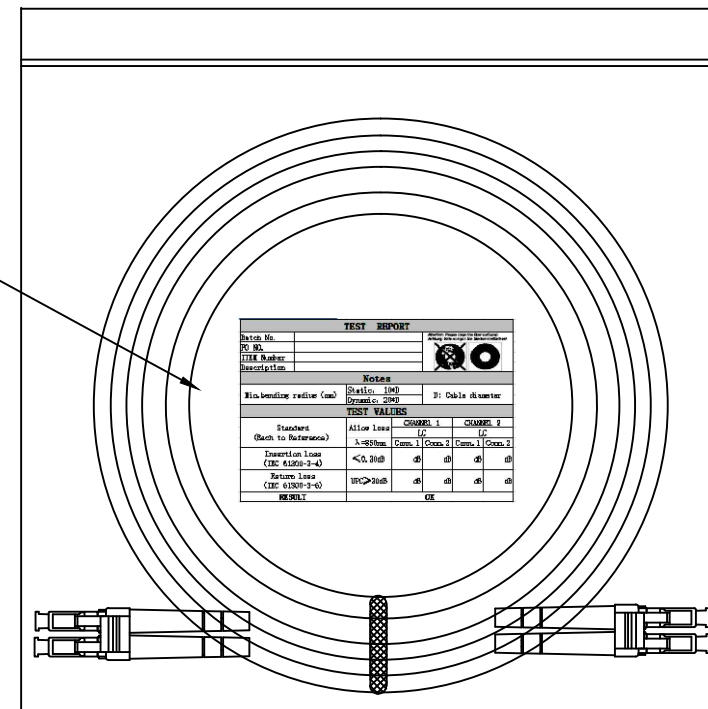


Chart:

| ITEM NO. | Length | FN. |
|----------|--------|------------|
| 1650928 | 1M | 29212c143 |
| 1650925 | 2M | 29212c143a |
| 1650924 | 3M | 29212c143b |
| | 5M | |
| | 10M | |

Renkforce

| | | | | | | | | |
|--------------|--|-------------------------------|---------------|------|---------|---------|--------|----------|
| CUSTOMER | | ITEM NO. | see the chart | | | | | |
| PRODUCT NAME | LC-LC Duplex Patch Cord OM4 2.0 Erika violet | | | | UNIT | MM | | |
| BY | CHK | NEW | 2021-1-7 | A | DRAWNBY | CHECKBY | APPOBY | DATE |
| | | REVISION RECORD MODIFICATIONS | DATE | REV. | Kerry | Kerry | | 2021-1-7 |