




Single Wallmount Cabinet with Openable Side Panels From Outside

Technical Features

Material: 1 / 1.2 / 1.5 mm steel
Max. Static Load: Up to 50 kg
Finish: Electrostatic Powder Paint
Color: RAL 7035 or RAL 9005

- » Steel frame
- » Glass door with cylindrical lock
- » Removable side panels from outside
- » 1 Pair of 19" Mounting Rails
- » RoHS compliant, UL Certificated
- » Flat packed (disassembled)

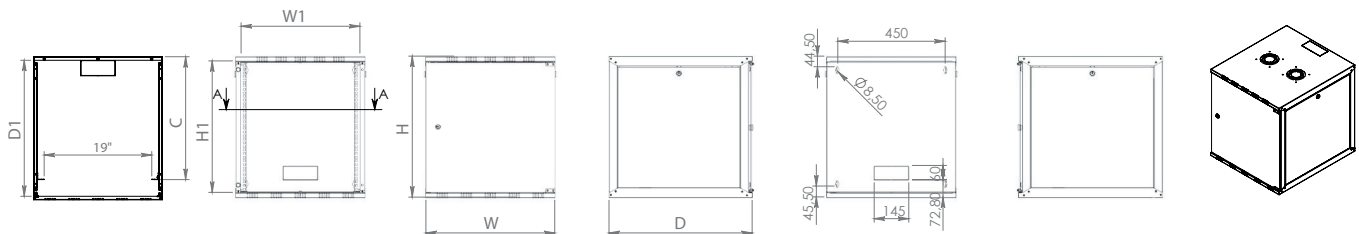

Wallmount Cabinet - RAL 7035 Light Grey / RAL 9005 Black

Height U	Outer width (W) mm	Outer depth (D) mm	Outer height (H) mm	Inner width (W1) mm	Inner depth (D1) mm	Inner height (H1) mm	19" rails adjustable depth range (C)	Weight kg	Part No. X=B (Black) X=G (Grey)
6	540	400	323	498	370	283	100-340	13	W06A40X
6	540	550	323	498	530	283	100-495	15	W06A54X
9	540	400	456	498	370	416	100-340	15	W09A40X
9	540	550	456	498	530	416	100-495	17	W09A54X
12	540	400	589	498	370	549	100-340	17	W12A40X
12	540	550	589	498	530	549	100-495	19	W12A54X
15	540	400	723	498	370	683	100-340	19	W15A40X
15	540	550	723	498	530	683	100-495	21	W15A54X

* The specifications and pictures are subject to change without notice.
 *All trade names referenced are the registered trademark of their respective owners.

