



## 10" PDU with Aluminum Profile 3 x Sockets

Art no.: PDU3B01

### Technical Features

10" Rack mount installation

Sockets: 3 x DIN 49440, 45° angled, VDE0620-1 compliant

1,8 m power cord H05VV-F 3 x 1,5 mm<sup>2</sup> with CEE7/7 plug

Profile: Aluminum alloy shell

Material: Fireproof Polypropylene


Rated input voltage: 230V AC 50/60 Hz

Max input current: 16A / 3500 W

Dimensions: 1U, 259 x 45 x 45mm

Color: RAL 9005 Black

### Technical Drawings

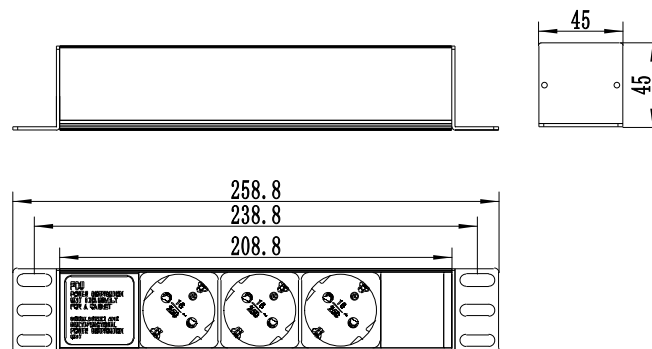

PDU3B01



4 052792 026719

Made in China

[www.logilink.com](http://www.logilink.com)



RoHS  
compliant



\* The specifications and pictures are subject to change without notice.  
\*All trade names referenced are the registered trademark of their respective owners.

## Package Contents

1 x 10" PDU with Aluminum Profile, 3 x Sockets

## Packaging Information

Packing Dimension	515 x 97 x 58mm
Packing Weight	0.8kg
Carton Dimension	515 x 295 x 195mm
Carton Q'ty	10pcs
Carton Weight	9kg



PDU3B01



4 052792 026719

Made in China

[www.logilink.com](http://www.logilink.com)



RoHS  
compliant



\* The specifications and pictures are subject to change without notice.  
\*All trade names referenced are the registered trademark of their respective owners.