

**Flat Cables**  
**AWG 28 Flat Ribbon Cable**

Pitch 1.0 mm



**SPECIFICATION:**

Operating Voltage (Nom.): 300 V  
 Operating Temperature: 0°C to 105°C  
 Dielectric Strength: 2,000 Vac



**MATERIAL:**

Material (Conductor):  
 Material (Sheath): PVC

**HANDLING:**

Packaging: ring

**RoHS**  
 COMPLIANT

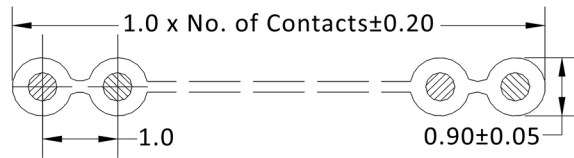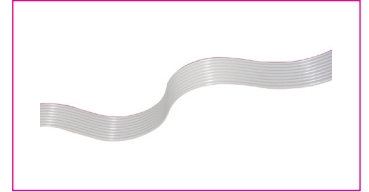

**Order Information**

Identifier:	No. of Contacts:	Pitch:	Colour:
<b>28AWG</b>	<b>#</b>	<b>RM1</b>	
Flat ribbon cable 28AWG 30.5 m	9: 9 poles	Pitch 1.0 mm	grey
	10: 10 poles		
	14: 14 poles		
	16: 16 poles		
	20: 20 poles		
	25: 25 poles		
	26: 26 poles		
	34: 34 poles		
	40: 40 poles		
	44: 44 poles		
	50: 50 poles		