

**Flat Cables**  
**AWG 28 Flat Ribbon Cable**

Pitch 1.27 mm



**SPECIFICATION:**

Operating Voltage (Nom.): 300 V  
 Operating Temperature: -20°C to 105°C  
 Dielectric Strength: 2,000 Vac



**ROHS**  
 COMPLIANT

**MATERIAL:**

Material (Conductor): copper, tin plated  
 Material (Sheath): PVC

**HANDLING:**

Packaging: ring

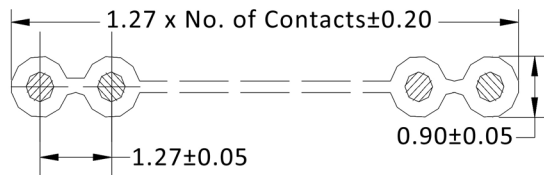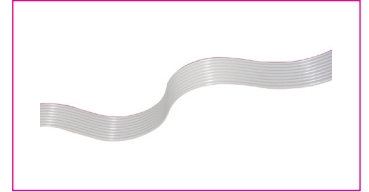

**Order Information**

Identifier:	No. of Contacts:	Colour:
<b>28AWG</b>	<b>#</b>	<b>GR</b>
Flat ribbon cable 28AWG 30.5 m	4: 4 poles	grey
	6: 6 poles	
	8: 8 poles	
	9: 9 poles	
	10: 10 poles	
	14: 14 poles	
	16: 16 poles	
	20: 20 poles	
	25: 25 poles	
	26: 26 poles	
	34: 34 poles	
	37: 37 poles	
	40: 40 poles	
	50: 50 poles	
	60: 60 poles	
	64: 64 poles	