

Waterproof USB Connector with HAN® Housing

USB 2.0-Connection + Cable

End 1: HAN® 3A-Conn. housing with

USB 2.0 Type A contact

End 2: Plug, USB 2.0 Type A

Protection: IP 65


(In closed state w. Hinged Cap)

Contacts: 4

Materials: Aluminium / Plastic

Contact plating: Gold-plated

Kit: Including Cap + sealing

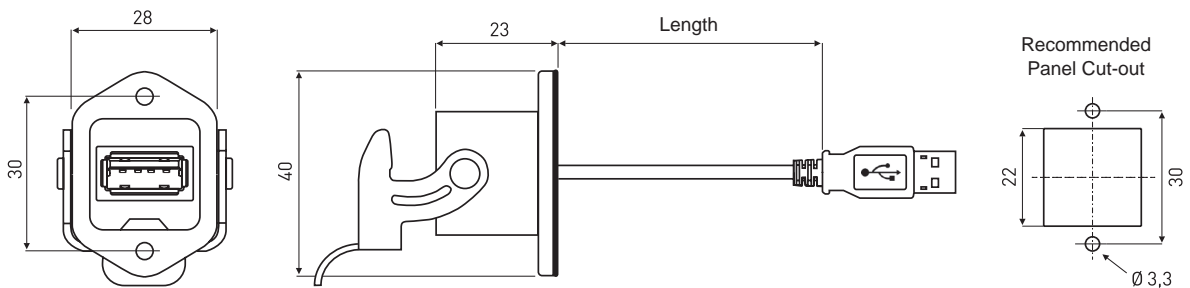

USB 2.0 - Connection Cable with HAN® housing

Cable length:	Housing/Type:	Part No:
1.8m	Plastic / With Cap	1310-0007-01
3.0m	Plastic / With Cap	1310-0007-02
1.8m	Metal / With Cap	1310-0007-03
3.0m	Metal / With Cap	1310-0007-04
1.8m	Metal / With Hinged Cap	1310-0007-05
3.0m	Metal / With Hinged Cap	1310-0007-06



Encitech AB
Rörkullsvägen 4
SE-302 41 HALMSTAD, Sweden

Tel.: +46-(0)35-15 13 90
Fax: +46-(0)35-15 13 99

www.encitech.com