


## Male & Female Terminal Connectors Pairs Boxed Set

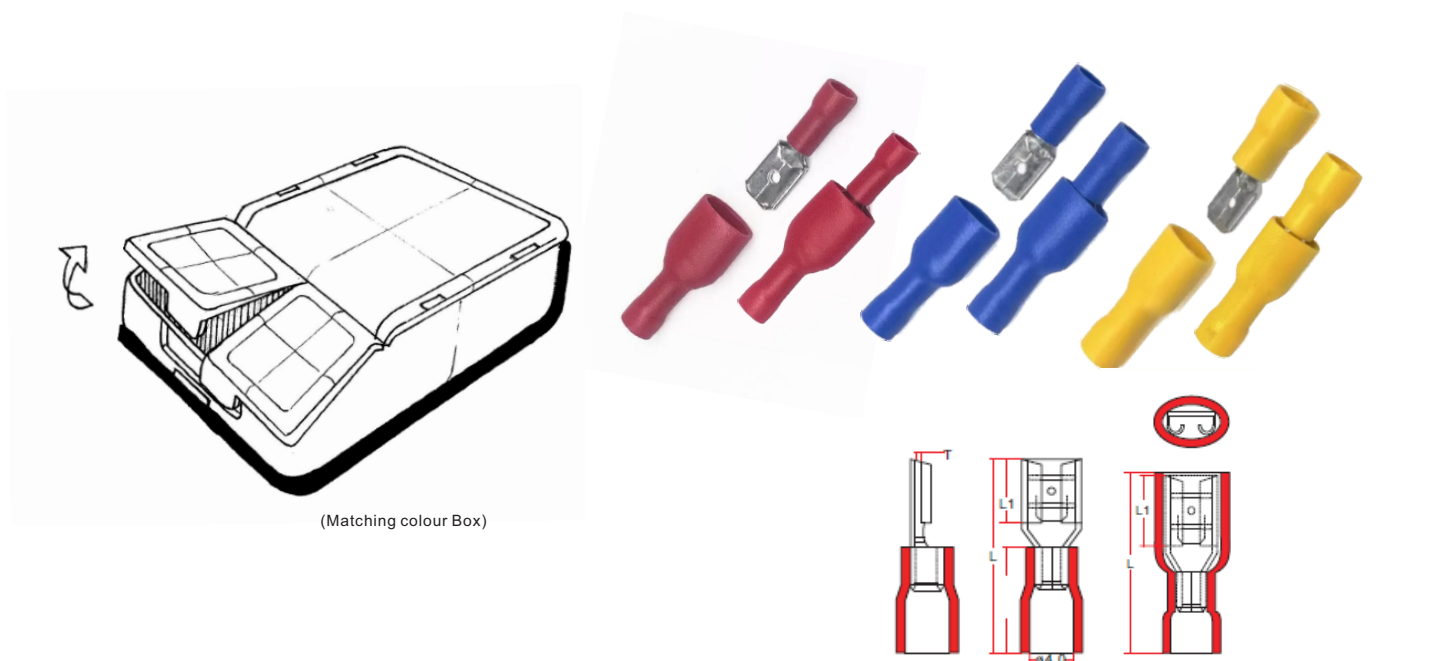

Best. Nr.	Part/No.	Wire range	TAB Size (mm)	T (mm)	W (mm)	L1 (mm)	L (mm)	QTY (Pairs)	Colour
1661663	517-2-2012-04	0.5~1.5mm <sup>2</sup> 22~16 AWG	2.80 x 0.80mm	0.8	2.8	6.5	21.0	70	Red
1661664	517-2-2013-04		4.80 x 0.80mm	0.8	4.8	6.5	23.0	70	
1661665	517-2-2014-04		6.40 x 0.80mm	0.8	6.4	7.7	25.0	70	
1661666	517-2-2015-05	1.5~2.5mm <sup>2</sup> 16~14 AWG	2.80 x 0.80mm	0.8	2.8	6.5	18.6	70	Blue
1661667	517-2-2016-05		4.80 x 0.80mm	0.8	4.8	6.5	20.0	70	
1661668	517-2-2017-05		6.40 x 0.80mm	0.8	6.4	7.5	22.0	70	
1661669	517-2-2018-08	4.0~6.0mm <sup>2</sup> 12~10 AWG	4.80 x 0.80mm	0.8	4.8	6.5	24.0	50	Yellow
1661670	517-2-2019-08		6.40 x 0.80mm	0.8	6.4	7.5	25.0	50	

Operating Temperature : 75°C max.

Material

Terminal : Brass

Insulation : PVC

Plating : TIN

Tolerance : ±0.2

This is a publication by Conrad Electronic SE, Klaus-Conrad-Str. 1, D-92240 Hirschau (www.conrad.com).

All rights including translation reserved. Reproduction by any method, e.g. photocopy, microfilming, or the capture in electronic data processing systems require the prior written approval by the editor. Reprinting, also in part, is prohibited. This data represent the technical status at the time of printing. Changes in technology and equipment reserved.

© Copyright 2017 by Conrad Electronic SE.