


Electronic Dimmer for Floor Light

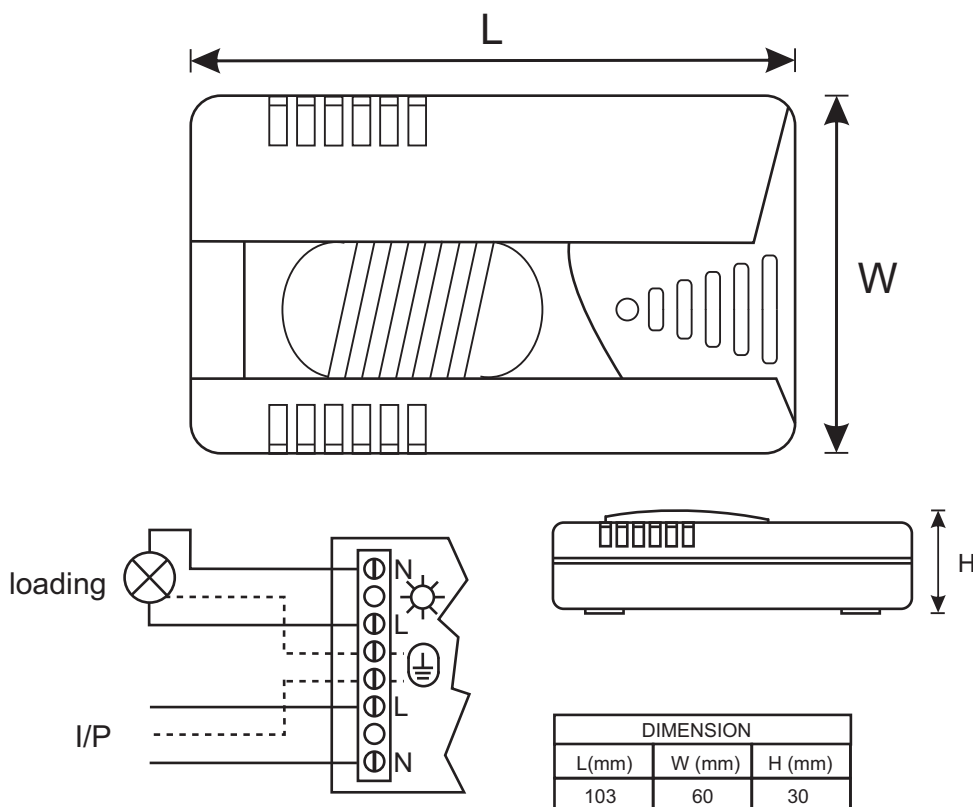

Technical Data

Input Voltage: 220 ~ 240V / AC 50/60Hz

Rated Loading: 60W ~ 300W

Ambient Temperature: 45°C

Casing Material: PC

Color Options: Black, White

Dimension: L: 103 x W: 60 x H: 30mm

Dimmable way: Foot slide