


Data Sheet

Push Button Switch

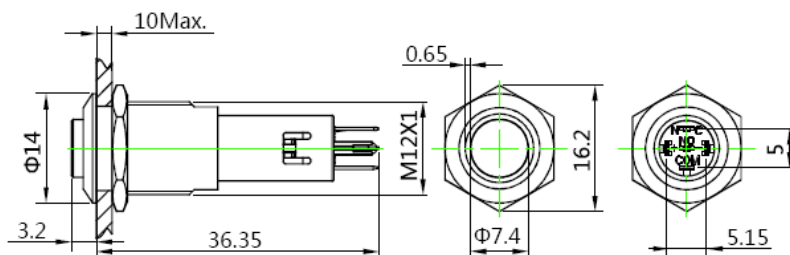

10 MAX: means the panel thickness, the max thickness for the panel no more than 10mm.

Specification

Mounting diameter	12 mm
Head shape	High round head
Operation type	Momentary / Latching
Contact structure	1NO1NC
Switch rating	48V / 2 A
Illumination type	Ring
Body material	Stainless steel
Operating and storage temperature	-20 to +55 °C
Operating and storage humidity	45 to 85 % RH
Base material	PA
IP rating	IP40

Item no.	Operation type	LED color	LED voltage
1661900	momentary	no LED	no LED
1661896	latching	no LED	no LED
1661892	momentary	Blue	12 V
1661894	momentary	Blue	24 V
1661901	momentary	Green	12 V
1661902	momentary	Green	24 V
1661891	momentary	Red	12 V
1661893	momentary	Red	24 V
1661888	momentary	White	12 V
1661895	momentary	White	24 V
1661897	latching	Blue	12 V
1661899	latching	Blue	24 V
1661889	latching	Green	12 V
1661890	latching	Green	24 V
1661903	latching	Red	12 V
1661904	latching	Red	24 V
1661898	latching	White	12 V
1661905	latching	White	24 V