


Datasheet

BN 1662010

V1_0712_01_en

Foot Switch

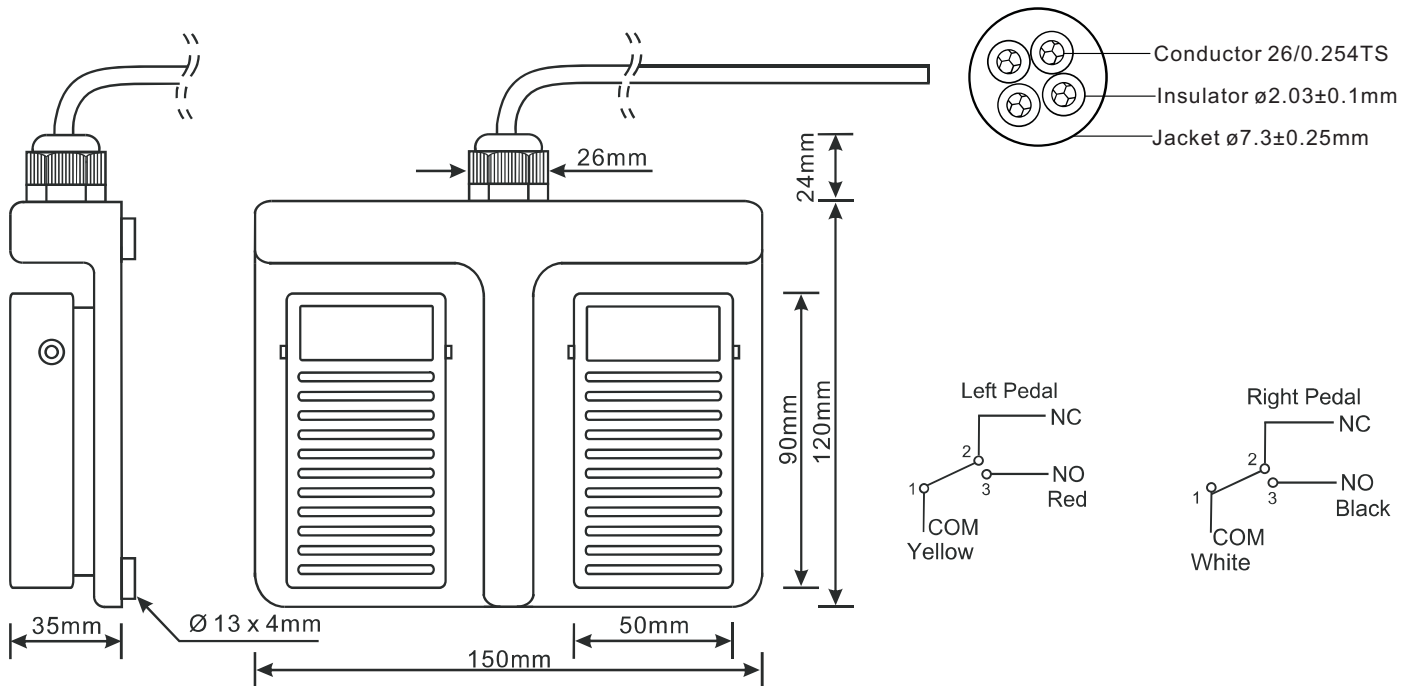

Material	Metal & Plastic
Voltage Rating	AC250V
Current Rating	16A
No. of Pedals	Two
Dimension	150x120x35 mm
Operating Temperature	-25°C~60°C
Operating Humidity	45%~85%RH
Storage Temperature	-10°C~75°C
Storage Humidity	0~80%RH
Tolerance	+/- 2.0mm
Cable standard	UL2464 16 AWG
Cable Length	1m

This is a publication by Conrad Electronic SE, Klaus-Conrad-Str. 1, D-92240 Hirschau (www.conrad.com).
 All rights including translation reserved. Reproduction by any method, e.g. photocopy, microfilming, or the capture in electronic data processing systems require the prior written approval by the editor. Reprinting, also in part, is prohibited. This data represent the technical status at the time of printing. Changes
 © Copyright 2018 by Conrad Electronic SE.