


Data Sheet

Foot Switch

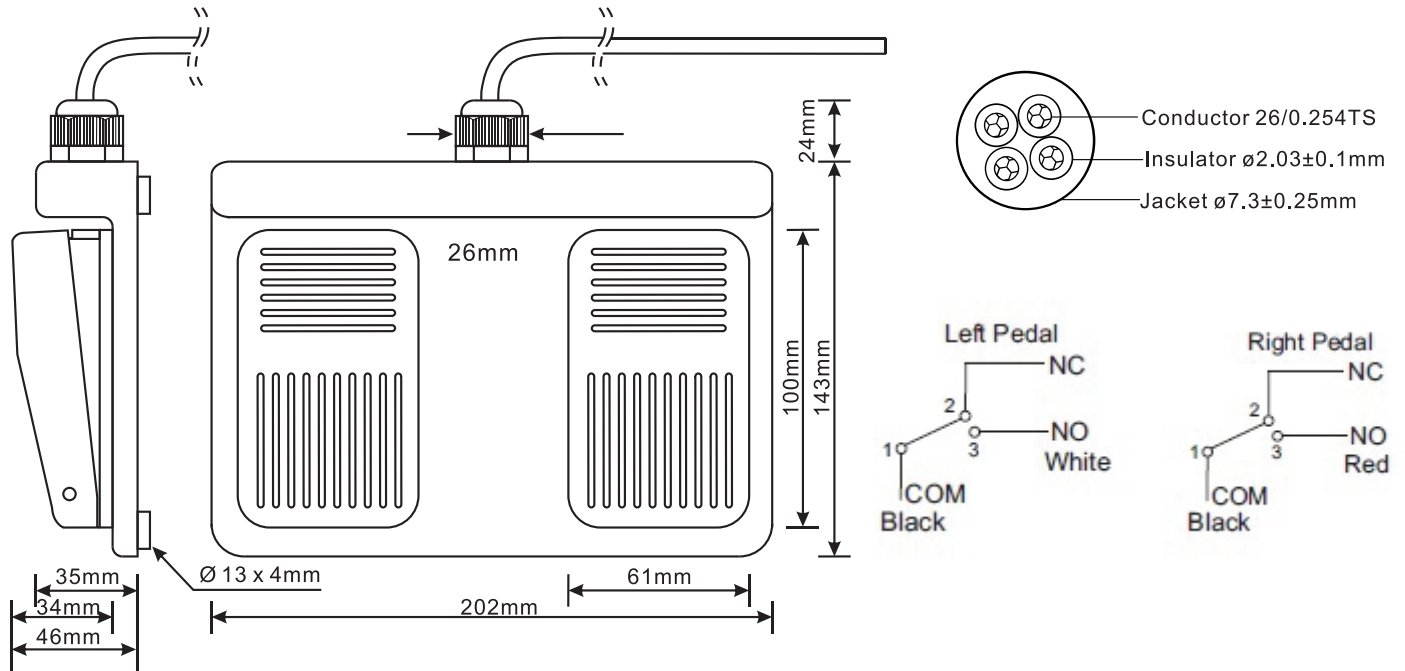

Material	Metal & Plastic
Voltage Rating	AC250V
Current Rating	10A
No. of Pedals	Two
Dimension.....	202x143x35 mm
Operating Temperature	-25°C~60°C
Operating Humidity	45%~85%RH
Storage Temperature	-10°C~75°C
Storage Humidity	0~80%RH
Tolerance	+/- 2.0mm
Cable standard	UL2464 16 AWG
Cable Length.....	1m