


## Crimp Connector Assortment set, 4300 pcs/set

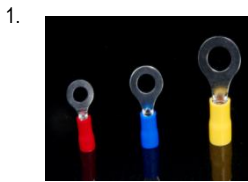

1. Insulated Ring Terminals  
0.5~1.5 mm<sup>2</sup> M4 Red  
Length: 20.1mm  
Screw dia. 4.3 mm 19A  
Thickness: 0.75 mm

100 pcs



2. Insulated Ring Terminals  
1.5~2.5 mm<sup>2</sup> M5 Blue  
Length:22.5mm  
Screw dia. 5.3mm 27A  
Thickness:0.8mm

100 pcs




3. Insulated Ring Terminals  
4~6 mm<sup>2</sup> M6 Yellow  
Length: 31.5 mm  
Screw dia. 6.4 mm 48A  
Thickness: 1 mm

100 pcs




4. Flat Pin Terminal Sleeve  
2.8 x 0.8 mm Red  
Length: 19 mm 10 A  
Wire range: 0.5 ~ 1.5 mm<sup>2</sup>

100 pcs

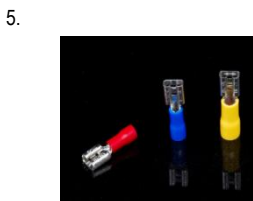


5. Flat Pin Terminal Sleeve  
6.3 x 0.8 mm Red  
Length: 21 mm 10 A  
Wire range: 0.5 ~ 1.5 mm<sup>2</sup>

100 pcs

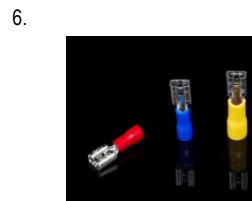


6. Flat Pin Terminal Sleeve  
6.3 x 0.8 mm Blue  
Length: 21 mm 15 A  
Wire range: 1.5 ~ 2.5 mm<sup>2</sup>

100 pcs

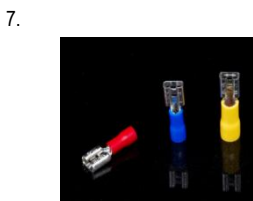

7. Flat Pin Terminal Sleeve  
6.3 x 0.8 mm Yellow  
Length: 25 mm 24 A  
Wire range: 4 ~ 6 mm<sup>2</sup>

100 pcs

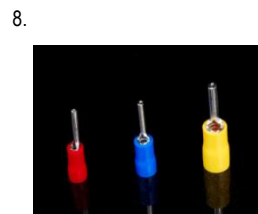

8. Insulated Pin Terminals  
0.5~1.5 mm<sup>2</sup> Red  
Length: 20 mm 19 A

100 pcs

# Datasheet

Item no. 1662130

V1\_04262018\_01\_en

9.



9. Insulated Pin Terminals  
1.5~2.5 mm<sup>2</sup> Blue  
Length: 20 mm 27 A

100 pcs

10.



10. Insulated Pin Terminals  
4~6 mm<sup>2</sup> Yellow  
Length: 25.5 mm 48 A

100 pcs


11.



11. Insulated Ring Terminals  
0.5~1.5 mm<sup>2</sup> Red  
Length: 21.5 mm  
Screw dia. 5.3 mm 19 A

100 pcs


12.

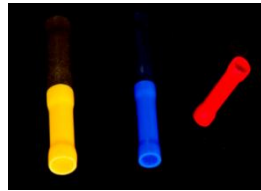

12. Push connector  
0.5 - 1.5 mm<sup>2</sup> Red  
Length: 26 mm 19 A  
Inner dia.: 1.7 mm

100 pcs


13.

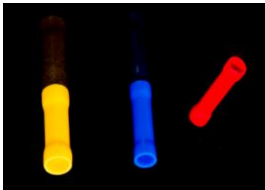

13. Push connector  
1.5~2.5 mm<sup>2</sup> Blue  
Length: 26 mm 27 A  
Inner dia. 2.3 mm

100 pcs

14.

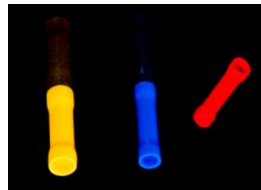

14. Push connector  
4 - 6 mm<sup>2</sup> Yellow  
Length: 26 mm 48 A  
Inner dia.: 3.4 mm

100 pcs

15.



15. Insulated Cord End Terminal  
0.5 mm<sup>2</sup> White  
Length: 14 mm 19 A

500 pcs

16.



16. Insulated Cord End Terminal  
0.75 mm<sup>2</sup> Gray  
Length: 14.6 mm 19 A

500 pcs


17.



17. Insulated Cord End Terminal  
1 mm<sup>2</sup> Red  
Length: 14.6 mm 19 A

500 pcs

18.

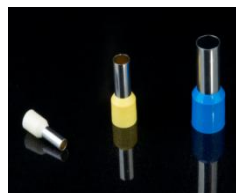

18. Insulated Cord End Terminal  
1.5 mm<sup>2</sup> Black  
Length: 14.6 mm 27 A

500 pcs

19.



19. Insulated Cord End Terminal  
2.5 mm<sup>2</sup> Blue  
Length: 15.2 mm 27 A

500 pcs

20.



20. Insulated Cord End Terminal  
4.0 mm<sup>2</sup> Gray  
Length: 16.5 mm 48 A

300 pcs

# Datasheet

Item no. 1662130

V1\_04262018\_01\_en

21.



21. Insulated Cord End Terminal  
 6.0 mm<sup>2</sup> Yellow  
 Length: 18 mm 48 A  
 100 pcs

Rated voltage.....	48V AC/ 60V DC
Material .....	Copper/ Brass
Operating temperature.....	-20 to +70° C
Storage temperature range.....	-20 to +70° C
Operating humidity range.....	35%~95%
Storage humidity range.....	35%~95%