


Datasheet

Item no. 1662195 – Red / 1662196 - Green

V1_08142018_01_en

Neon Signal Indicator with cable, 230V, Ø10 mm x (L) 200 mm

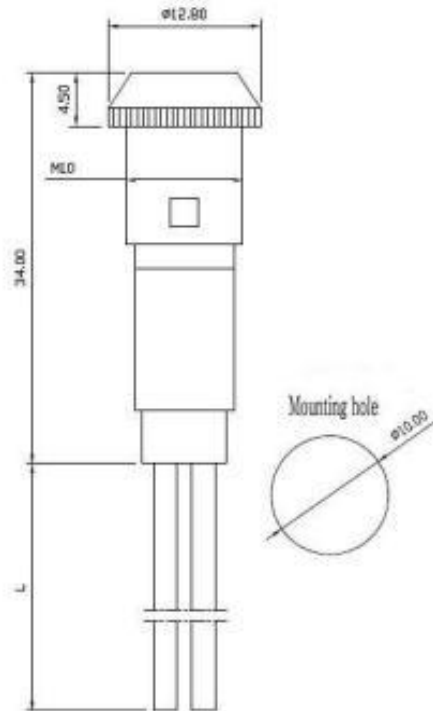

Voltage Rating:	230V, 50/60 Hz
Current Rating:	2 mA
Mounting Hole:	Ø10 mm
Mounting Panel Thickness:	0.8 – 3 mm
Silicon Wire Heat Resistance:	180°C
Life Time:	25000 hours
Connection:	Open End
Material of Lamp Base:	PC
Material of Lamp Holder:	Nylon/ PBT
Operating Temperature & Humidity:	0°C to 100°C; 10-80% RH
Storage Temperature & Humidity:	-20°C to 120°C; 10-80% RH