


Data Sheet

5.5 mm Low Power Plug & Cable



Drawing:

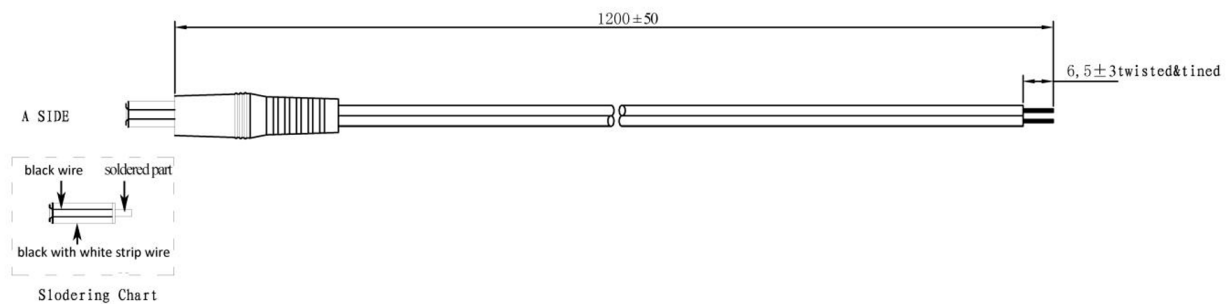

Technical data

Cable length: 1.20 m

Color: Black

Connection A: Low-voltage plug

Connection B: Open cable ends

Inner diameter: 2.10 mm

Outside diameter: 5.50 mm

Electrical requirements:

The rate of conductivity is 100%

No short or open circuit is allowed, no circuit misplacement is allowed.

Conductor resistance < 1 Ω

Voltage: max. 48 V DC

Insulation resistance $\geq 20 \text{ M}\Omega$