

## DinO One RS

### Description:


- Installation on DIN rail, one module wide (17.5 mm.)
- Its small size allows mounting in existing cabinets with little space available
- Lateral sphere easy to program by movable trippers
- Interchangeable backup battery (= 150 h)
- Switch for manual control with three positions: automatic, permanent on and permanent off
- Sealable clear window to avoid unauthorised handling
- Minimum operation time 2 hours

### Technical specifications:

Power supply:	230 Va.c., 50-60 Hz;	
Simple contact:	N/O	
Switching capacity:	16 (4) A / 250 Va.c.	
Programming	Weekly / 2 hrs.	
Backup	150 h	
Max. Recomm. Load	Incandescent	2500 W
	Fluorescent	1200 VA
	Halogen 12 Va.c.	2000 VA
	Halogen 230 Va.c.	2500 W
	Low Consumption	900 VA
	LED	1000 VA
Max. cross section:	4 mm <sup>2</sup>	
Protection degree:	IP 20 according to EN 60529	
Operating temp.:	-10 °C to +45 °C according to EN 60730-2-7	



ESQUEMA DE DIMENSIONES / DIMENSIONS DIAGRAM

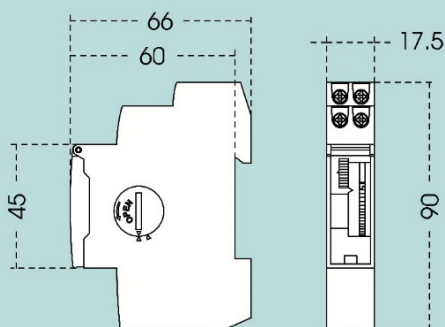

ESQUEMA DE CONEXIONES / CONNECTION DIAGRAM

