


Test Lead SLK4...-E...

Highly flexible, with insulation in PVC or silicone with stackable Ø 4 mm MULTILAM plugs with rigid insulating sleeve on both ends.

SLK4...-E...

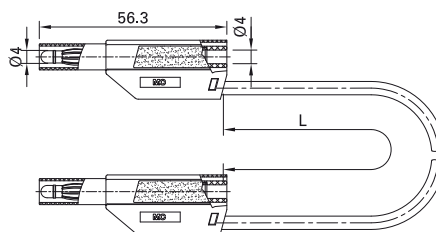

Order No.	Type	Rated voltage/current	Lead		Lead lengths L [cm] ¹⁾	*Colors ¹⁾
28.0127-□*	SLK4075-E/N	1000 V, CAT II / 15 A 600 V, CAT III / 15 A	PVC 0,75 mm ²	Ni CE c UL us	025 050 075 100 150 200	20 21 22 23 24 25 26 27 28 29
49.0126-□*	SLK410-E/N	1000 V, CAT II / 19 A 600 V, CAT III / 19 A	PVC 1,0 mm ²	Ni CE c UL us	025 050 075 100 150 200	20 21 22 23 24 25 26 27 28 29
28.0126-□*	SLK410-E/SIL	1000 V, CAT II / 19 A 600 V, CAT III / 19 A	SIL 1,0 mm ²	Au CE c UL us	025 050 075 100 150 200	21 22 23
49.0079-□*	SLK410-E/N SIL	1000 V, CAT II / 19 A 600 V, CAT III / 19 A	SIL 1,0 mm ²	Ni CE c UL us	025 050 075 100 150 200	20 21 22 23 24 25 26 27 28 29
28.0124-□*	SLK425-E	1000 V, CAT II / 32 A 600 V, CAT III / 32 A	PVC 2,5 mm ²	Au CE c UL us	025 050 075 100 150 200	20 21 22 23 24 25 26 27 28 29
28.0125-□*	SLK425-E/N	1000 V, CAT II / 32 A 600 V, CAT III / 32 A	PVC 2,5 mm ²	Ni CE c UL us	025 050 075 100 150 200	20 21 22 23 24 25 26 27 28 29

¹⁾ Other color and/or length combinations available on request.