



WALL SWITCH



Open or Close my blinders, remotely

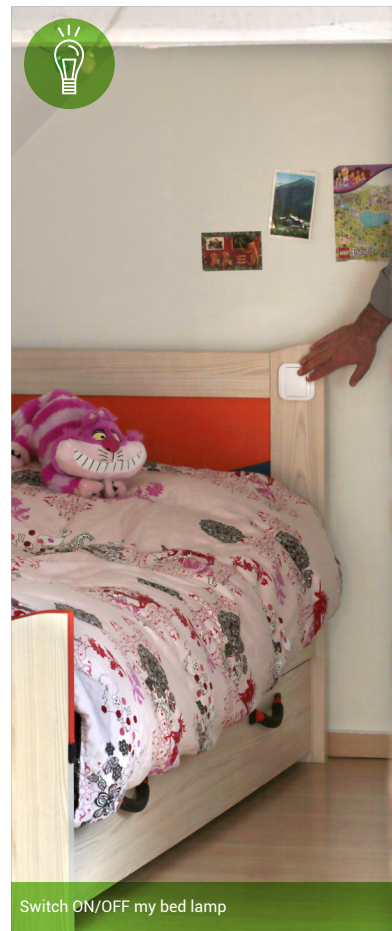

Switch ON/OFF my bed lamp

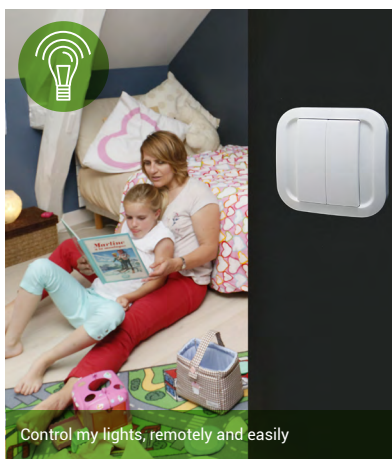

Control my lights, remotely and easily



Switch ON or OFF my alarm system, while I'm passing the doorway

TECHNICAL SPECIFICATIONS

Power source: Magneto-resistive (no battery)
4 buttons - 2 channels or 1 button - 1 channel (both version included)
Wall mounting using adhesive bonding (included) or screws (not included)
Operational temperature: 0°C to 40°C
Altitude: 2.000m
Radio: EnOcean® Protocol
EEP F6-02-01
Frequency: depending on Region
Range: 30m indoor
Dimensions: 80*80*15mm

PRODUCT REFERENCE

Frequency 868,3 MHz - CWS-2-1-01 - EAN: 3700313920077 - Cozy White

Frequency 908,42 MHz - CWS-2US-1-01 - EAN: 3700313920688 - White US

CERTIFICATIONS AND STANDARDS - EUROPE

EN 60950-1:2006+A11:2009
+A1:2010+A12:2011+A2:2013
EN 301489-3 V1.6.1
EN 61000-3-2:2013,
EN 61000-3-3:2013
EN 300220-2:V3.1.1
EN 62479:2010

CERTIFICATIONS AND STANDARDS - USA

FCC & IC Rules

