


RELAY SWITCH 1 CHANNEL

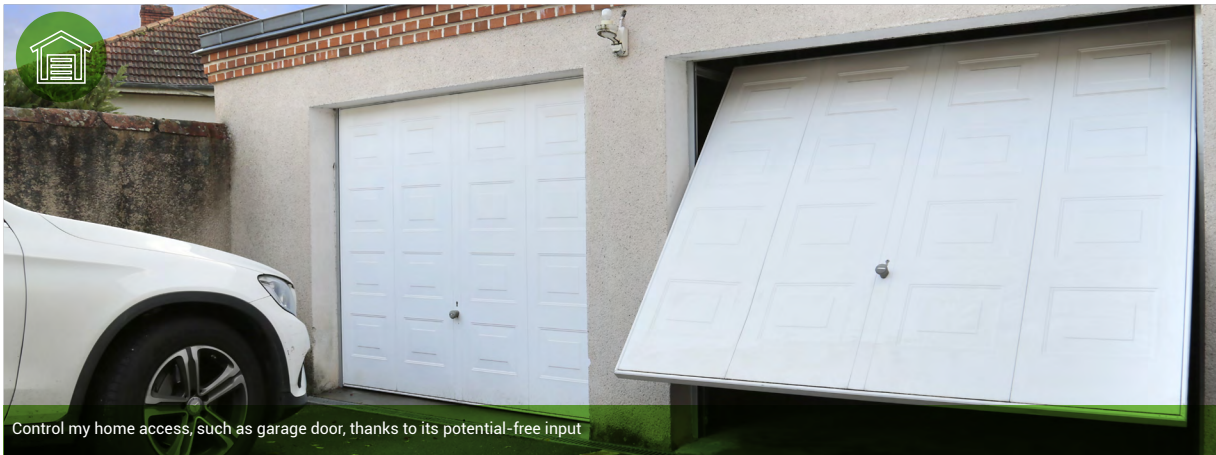


Control my home access, such as garage door, thanks to its potential-free input



Switch ON / OFF my appliances remotely, directly from the wall



Control my boiler and centralized heating system, thanks to its potential-free input

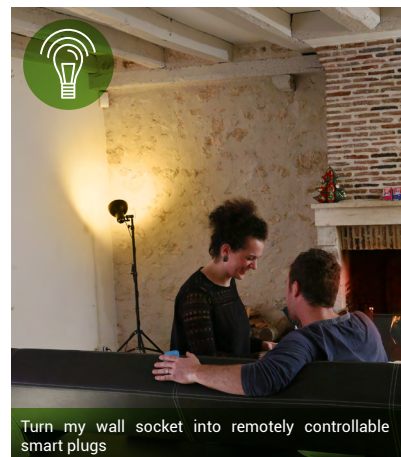


Turn my wall socket into remotely controllable smart plugs

TECHNICAL SPECIFICATIONS

Power supply: 230V AC +/-10%
50Hz
Switching capabilities (resistive Load):
230VAC Max. 10A (2.300W)
30VDC Max. 10A
Self-consumption: <1W
Operational temperature: 0°C to 40°
Radio: EnOcean® protocol
868.3MHz bidirectional
EEP: D2-01-0E
Range: 30m
2 inputs for existing wired wall switch(es)
Dimension: 40*45*16,9mm

CERTIFICATIONS AND STANDARDS - EUROPE

EN60669-1:1999+A1:02
+A2:08
EN60669-2-1:2004
+A1:09+A12:10
EN300220-2 V3.1.1
EN301489-01 V2.1.1
EN301489-03 V2.1.1
EN62479:2010

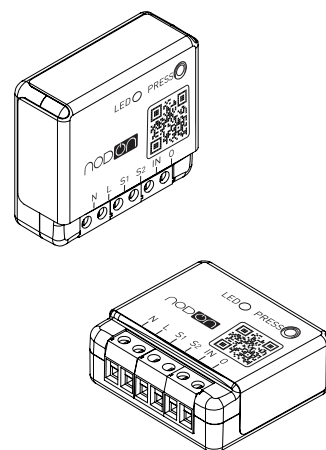

PRODUCT REFERENCE

SIN-2-1-01 - EAN: 3700313921425