


RELAY SWITCH 2 CHANNELS



Turn my lights into smart, remotely controllable lighting system



Create a Back & Forth system, without breaking my walls

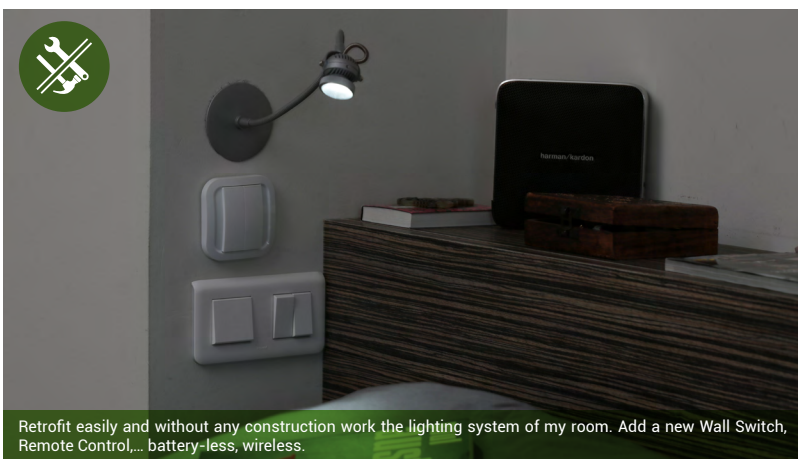

Retrofit easily and without any construction work the lighting system of my room. Add a new Wall Switch, Remote Control,... battery-less, wireless.





Switch ON / OFF my appliances remotely, directly from the wall

TECHNICAL SPECIFICATIONS

Power supply : 230V AC +/-10%
50Hz
Maximum output power: 2*1.1kW
(Resistive load)
Self-consumption: <1W
Operational temperature: 0°C to 40°
Radio: EnOcean® Protocol
EEP: D2-01-12
868.3MHz Bidirectional
Range: 30m
2 inputs for existing wired wall
switch(es)
Dimension – 40*45*16,9mm

CERTIFICATIONS AND STANDARDS - EUROPE

EN60669-1:1999+A1:02+A2:08
EN60669-2-1:2004+A1:09+A12:10
EN300220-2 V3.1.1
EN301489-01 V2.1.1
EN301489-03 V2.1.1
EN62479:2010

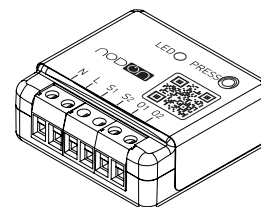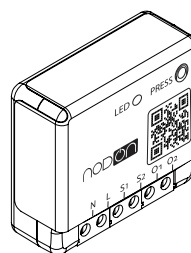

PRODUCT REFERENCE

SIN-2-2-01 - EAN: 3700313921371