


Peter

Fan

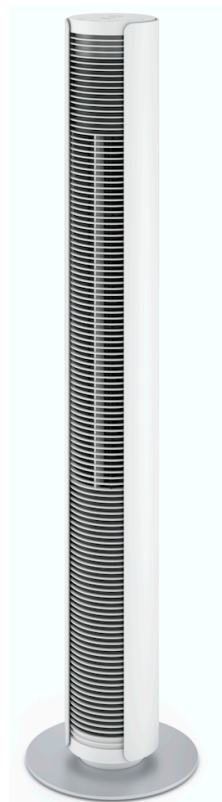

Description / features

Tower fan with large surface of air outlet and swing mode for an optimal distribution of the cooling air in the room – natural breeze mode simulates natural wind conditions to ensure an even more pleasant cooling effect – 3 speed levels – timer (1-7h) – remote control – removable and washable air filter – carrying handle – touch panel (touch-sensitive buttons) – suitable for bedrooms, LEDs disappear after the setting is done – air volume: up to 500 m³/h

Colours

white/silver
black/silver

EAN/UPC

0802322008159
0802322008210

Art. - No.

P-012
P-013

Logistics

	20'	40'	40'HQ
Container 1 master box	370	740	800
Product per pallet	21		
Loading port	Beijiao (Shunde)		

Technical data

Voltage	220-240V/50Hz
Power	36-60 W
Material	ABS, Aluminium
Room size	40 m ² / 100 m ³
Certification	CE, RoHS, WEEE

Dimensions and weight: (in kg and mm)

	length	height	depth	cbm	weight
Product (tower 135 diameter)	240	1100	240	0.063	6
Gift box	275	1140	201	0.063	8.15
Master (1)	290	1155	215	0.072	8.9

All pictures and technical data is approximate and subject to modification.