

Product information

95 05 10 SB

Electricians' Shears



- Precision finish with micro-toothing for a clean, non-slip cut
- Cutting edge with integrated cable cutter
- With plastic belt pouch
- With crimp area for wire ferrules up to 6.0 mm²
- Handles with multi-component grips, glass fibre reinforced
- Universal shears for electricians
- Cutting edges made from stainless steel, hardness of cutting edges 56 HRC
- Not suitable for cutting solid conductors
- With plastic belt pouch

General

Article No.	95 05 10 SB
EAN	4003773082125
Head	polished
Handles	with multi-component grips, glass fibre reinforced plastic
Weight	135 g
Dimensions	190 x 130 x 32 mm
REACH compliant	does not contain SVHC
RoHS compliant	not applicable

Technical details

Capacity in square millimetres	6.0 mm ²
--------------------------------	---------------------


technical change and errors excepted




Securely stowed and always at hand



95 05 10 SB: Fast, easy crimping

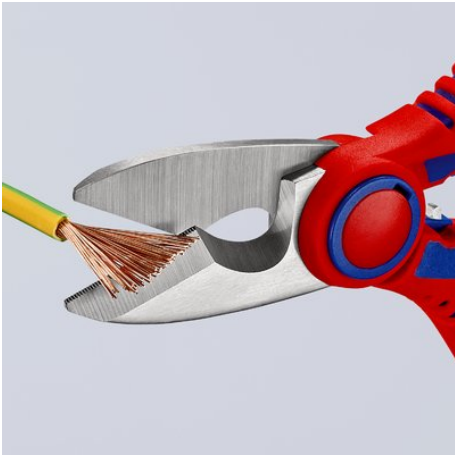

No slipping thanks to micro-serration

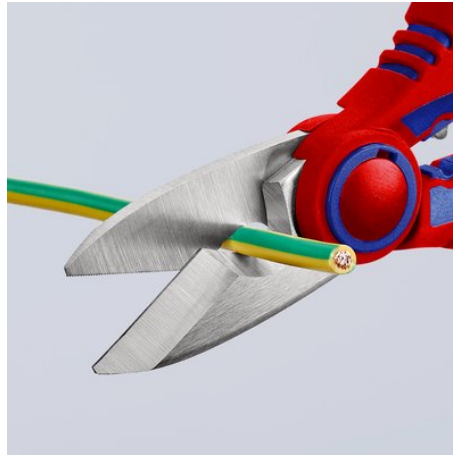

Integrated cable cutter

