


Datenblatt

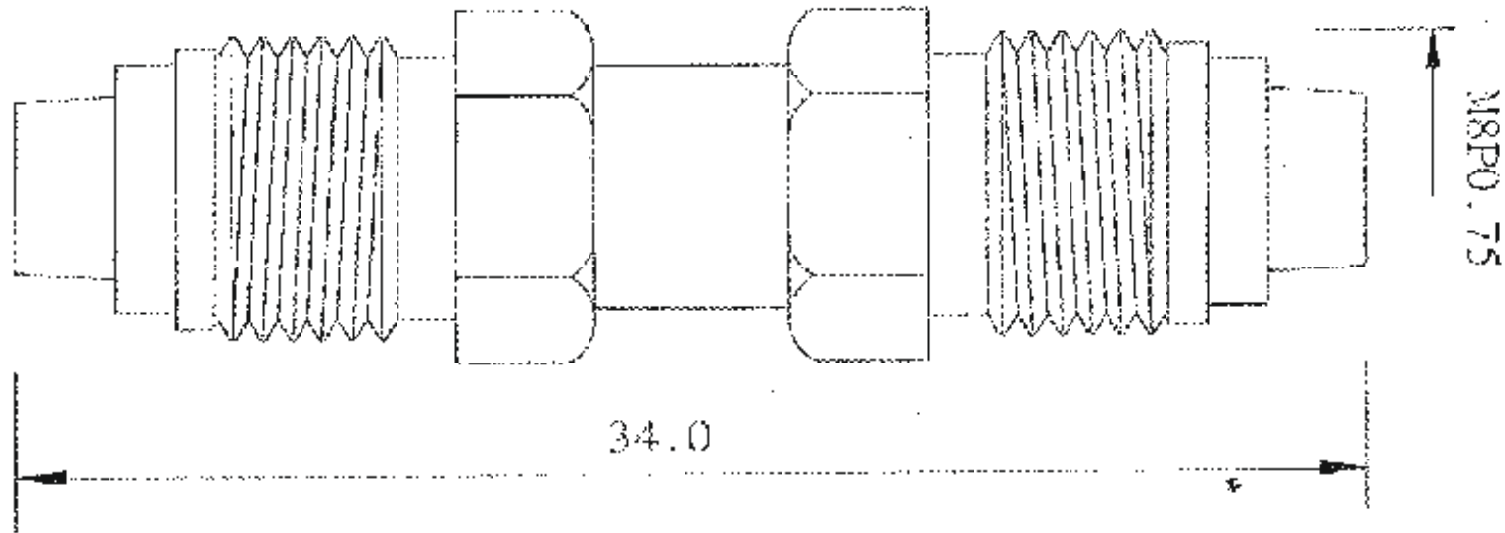

Impedance	50 Ω
Frequency range	0 - 10 GHz
USBR (Average) maximum	1.12 dB
Insulation resistance	2.5 x 10 ¹¹ Ω
Center contact resistance	< 0.001 Ω
Outer contact resistance	5 x 10 ⁻³ Ω
Test voltage	1000 V rms
Working voltage	500 V rms
Insertion loss (dB)	0.1 dB (average)

No.	Description	Material	Finish
4	Sub	Brass	Nickel
3	Insulation	Diecast	White
2	Contact	Brass	Gold
1	Body	Brass	Nickel