
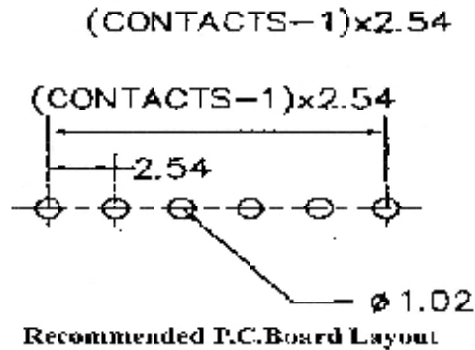


# Datenblatt

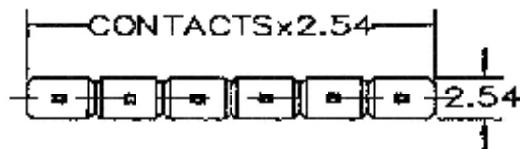

## SPECIFICATIONS

Current Rating: 3 Amperes  
 Insulation Resistance: 1000MΩ Min  
 Dielectric Withstanding: 600V AC/DC  
 Contact Resistance: 20mΩ Max.  
 Operating Temperature: -40°C to +105°C

## MATERIALS

Contact Material: Copper Alloy  
 Contact Plating: Gold / Tin over Nickel  
 Insulator: Glass Filled Polyester (UL 94V-0)  
 P.B. I or Nylon-6 I  
 All materials must be RoHS compliant.

Dimensions(mm)		
A	B	C
10.80	5.80	> 50

