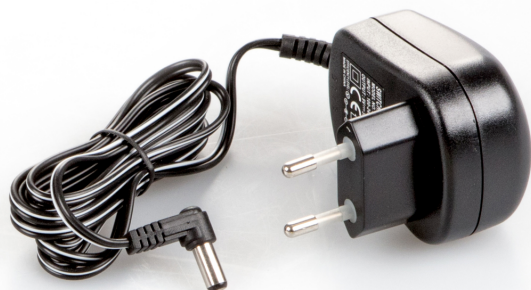


KERN 440-902

External mains adapter, EU

KERN

Product information

GTIN/EAN number	4045761013193
REACH classification	no prohibited substances

Pictograms

STANDARD



Category

Brand	KERN
Product category	Balance
Product group	Power adapter

Construction

Dimension (W×D×H)	52×37×30 mm
-------------------	-------------

Power Supply

Power supply type	Power adapter
Plug-in power supply / adapter for countries - included with the delivery	EURO CH
Input voltage power supply / power [Max]	100 V - 240 V AC, 50 / 60 Hz
Input voltage device / power [Max]	9 V, 300 mA
Power socket for mains adapter	Hollow plug, inside minus, Ø inside 2,1 mm, Ø outside 5,5 mm, long 12 mm

Environmental conditions

Storage temperature [Min]	-20 °C
Storage temperature [Max]	60 °C

Approval

CE mark	✓
---------	---

Packing & Shipping

Delivery time	1 d
Dimensions packaging (W×D×H)	85×85×50 mm
Shipping method	Parcel service
Net weight approx.	0,25 kg
Gross weight approx.	0,30 kg
Shipping weight	0,255 kg