


The finest cut result available with the smoothest lead-end result

Lindström Ultra-Flush® Cutters are engineered with an unwavering commitment to precision. The cutting-edge design ensures an ultra-close, clean and flush cut every time, leaving no room for imperfections. Ideal for intricate tasks where precision is paramount. Mostly used within electronics assembly, jewelry, watchmaking, medical device manufacturing, craftsmanship and model building.

- The finest cut result available with the smoothest lead-end result
- Exceptional solderability
- Ultimate choice for minimizing component and lead-shock
- Perfect for use in close tolerance electronics, aerospace, defense and medical device manufacturing

		XS Size		S Size		M Size		L Size	
		Bi-Material	Mono-Material	Bi-Material	Mono-Material	Bi-Material	Mono-Material	Bi-Material	Mono-Material
Diagonal Cutters	Oval	RX 8132	8132	RX 8142	8142	RX 8152	8152	RX 8162	8162
	Tapered	RX 8135	8135	RX 8145	8145	RX 8155	8155	RX 8165	8165
	Tapered & Relieved	RX 8138	8138	RX 8148	8148	RX 8158	8158	RX 8168	8168
	Extra Accessibility	RX 8138MX							
Oblique Cutters	45 Degrees			8248Q					

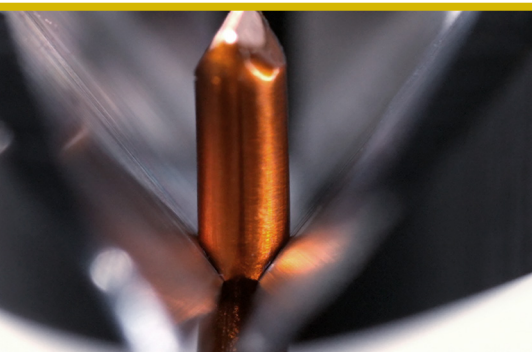

ULTRA FLUSH® CUTTER

