



XL6019

Step-Up Adjustable Voltage Regulator

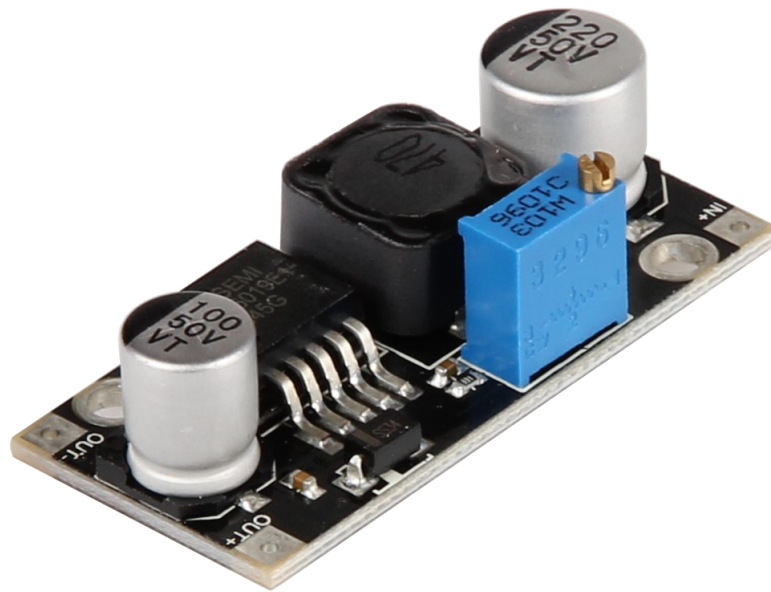

Technical Specifications

Model	XL6019 (Step-Up adjustable voltage regulator)
Article No.	SBC-XL6019
Input Voltage	5 - 40V DC
Output Voltage	5 - 40V DC (adjustable via potentiometer)
Input Current	Max. 5A
Special Features	High efficiency (up to 94%) Integrated MOSFET-Amplifier
Dimensions	50 x 28 x 13mm
Scope of Delivery	XL6019
EAN	4250236816937

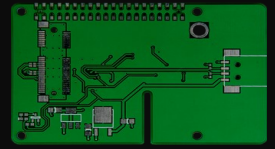

XL6019

Step-Up Adjustable Voltage Regulator

