



TECHNICAL DATA SHEET

30pcs Hook & Loop - tape assortment for bundling

Item No.: 201711CA004

This high-quality and extensive Hook & Loop tape set with 30 parts, in three sizes and two colors in the lengths 10, 15 and 20 cm offers extensive application possibilities. These absolutely stable Hook & Loop tape have a very good tensile strength, are reusable and can be locked on both sides as well as on full length. Thus, even larger cable glands or objects can be reliably bundle or fix.


Because of this flexibility in the application Hook & Loop products are an ideal aid in the job, hobby, household and leisure.

Further applications are found e.g. in the field of cable bundling, fixation of plants, stage technology and much more.

Reusability makes Hook & Loop tape an environmentally friendly alternative to traditional cable ties.



Material	Polyamide
Operating temperature	-10°C ~75°C
Meilting point	Hook - 230°C / Loop - 180°C
Tensile strength	Initial 8.3N/cm²
	After 1000 times 6.7N/cm²
	Afer 5000 times 6N/cm²
Peel strength	Initial 2.5N/cm²
	After 1000 times 2.1N/cm²
	Afer 5000 times 1.6N/cm²
Stear strength	9.8N/cm²

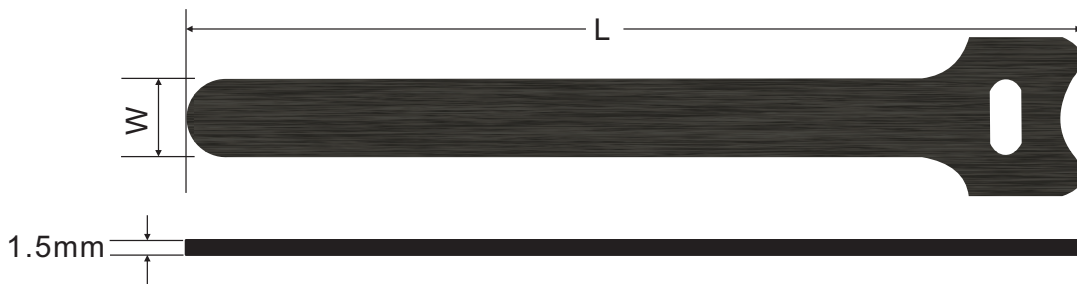

L	W	Bundle (max.)	Color	pcs
100 mm	13 mm	25 mm	Black	5
100 mm	13 mm	25 mm	Grey	5
150 mm	13 mm	39 mm	Black	5
150 mm	13 mm	39 mm	Gery	5
200 mm	13 mm	55 mm	Black	5
200 mm	13 mm	55 mm	Grey	5