

PRODUCT DATASHEET

ENDURA STYLE Wall Sensor 12 W DG

ENDURA STYLE WALL | Slim LED luminaires with high light output and optional sensor



AREAS OF APPLICATION

- Outdoor
- Entrance lighting
- Building facades

PRODUCT BENEFITS

- Energy-efficient thanks to LED technology
- 5 years guarantee
- Easy and quick installation

PRODUCT FEATURES

- Very bright and functional outdoor LED luminaires
- Type of protection: IP44
- Die-cast aluminum housing
- Available in two housing colors
- Available with and without motion sensor



TECHNICAL DATA


Electrical data

| | |
|-----------------|---------------|
| Nominal wattage | 12.20 W |
| Operating mode | Mains voltage |
| Nominal voltage | 220...240 V |
| Mains frequency | 50/60 Hz |

Photometrical data

| | |
|---------------------------|------------|
| Color temperature | 3000 K |
| Color rendering index Ra | >80 |
| Light color (designation) | Warm White |
| Luminous flux | 740 lm |

Dimensions & weight

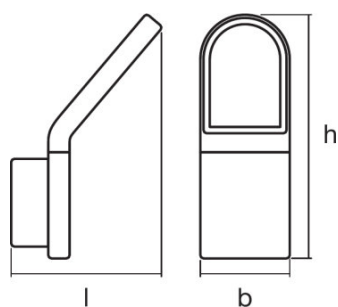

| | |
|----------------|-----------|
| Length | 168.0 mm |
| Width | 100.0 mm |
| Height | 273.0 mm |
| Product weight | 1300.00 g |

Colors & materials

| | |
|----------------|-----------|
| Body material | Aluminum |
| Housing color | Dark gray |
| Product color | Dark gray |
| Cover material | Glass |

Temperatures & operating conditions

| | |
|---------------------------|-------------|
| Ambient temperature range | -20...40 °C |
|---------------------------|-------------|

Lifespan

| | |
|-----------------|---------|
| Lifespan | 30000 h |
|-----------------|---------|

Additional product data

| | |
|--------------------------|---------|
| Mounting type | Surface |
| Mounting location | Wall |

Capabilities

| | |
|---------------------------|----------|
| Dimmable | No |
| Type of connection | Terminal |

Certificates & standards

| | |
|---------------------------|------|
| Protection class | I |
| Type of protection | IP44 |

EQUIPMENT / ACCESSORIES

- Complete mounting and connecting accessories included

LOGISTICAL DATA

| Product code | Product description | Packaging unit (Pieces/Unit) | Dimensions (length x width x height) | Volume | Gross weight |
|---------------|----------------------------------|------------------------------|--------------------------------------|-----------------------|--------------|
| 4058075033238 | ENDURA STYLE Wall Sensor 12 W DG | Shipping carton box 4 | 425 mm x 285 mm x 315 mm | 38.15 dm ³ | 6879.00 g |

The mentioned product code describes the smallest quantity unit which can be ordered. One shipping unit can contain one or more single products. When placing an order, for the quantity please enter single or multiples of a shipping unit.

REFERENCES / LINKS

For Guarantee see

- ▶ www.ledvance.com/guarantee

DISCLAIMER

Subject to change without notice. Errors and omission excepted. Always make sure to use the most recent release.