

PRODUCT DATASHEET

ENDURA STYLE Shield SQ 11 W DG

ENDURA STYLE SHIELD | Luminaires with modern design and light outlet up and down



AREAS OF APPLICATION

- Outdoor
- Building facades
- Entrance lighting

PRODUCT BENEFITS

- Energy-efficient thanks to LED technology
- 5 years guarantee
- Easy and quick installation

PRODUCT FEATURES

- Bright and functional outdoor LED luminaires
- Type of protection: IP44
- Die-cast aluminum housing
- Available in round and square form



TECHNICAL DATA


Electrical data

Nominal wattage	10.50 W
Operating mode	Mains voltage
Nominal voltage	220...240 V
Mains frequency	50/60 Hz

Photometrical data

Color temperature	3000 K
Color rendering index Ra	>80
Light color (designation)	Warm White
Luminous flux	410 lm
Luminous efficacy	39 lm/W

Dimensions & weight

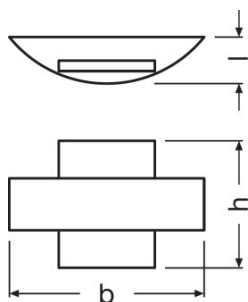

Length	60.0 mm
Width	240.0 mm
Height	142.0 mm
Product weight	740.00 g

Colors & materials

Body material	Aluminum
Housing color	Dark gray
Product color	Dark gray
Cover material	Polymethylmethacrylate (PMMA)

Temperatures & operating conditions

Ambient temperature range	-20...40 °C
---------------------------	-------------

Lifespan

Lifespan	30000 h
-----------------	---------

Additional product data

Mounting type	Surface
Mounting location	Wall

Capabilities

Dimmable	No
Type of connection	Terminal

Certificates & standards

Protection class	I
Type of protection	IP44
Standards	CE

EQUIPMENT / ACCESSORIES

- Complete mounting and connecting accessories included

LOGISTICAL DATA

Product code	Product description	Packaging unit (Pieces/Unit)	Dimensions (length x width x height)	Volume	Gross weight
4058075031753	ENDURA STYLE Shield SQ 11 W DG	Shipping carton box 6	430 mm x 300 mm x 290 mm	37.41 dm ³	6694.00 g

The mentioned product code describes the smallest quantity unit which can be ordered. One shipping unit can contain one or more single products. When placing an order, for the quantity please enter single or multiples of a shipping unit.

REFERENCES / LINKS

For Guarantee see

- ▶ www.ledvance.com/guarantee

DISCLAIMER

Subject to change without notice. Errors and omission excepted. Always make sure to use the most recent release.