
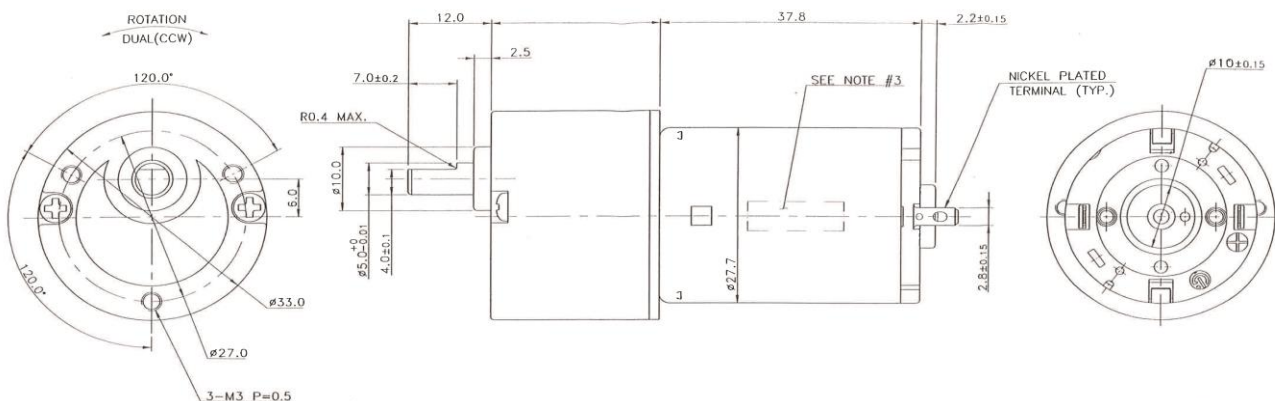


MODEL	VOLTAGE		NO LOAD		AT MAXIMUM EFFICIENCY				STARTING		max. OUTPUT POWER W	POLES	CAPACITOR	BRUSHES	REDUCTION RATIO
	Operating Range VDC	Nominal VDC	Speed rpm	Current A	Speed rpm	Current A	Torque mNm	Output Power W	Current A	Torque mNm					
33GN2738-132-GV-5 312:1	6,0-15,0	12,0	17	0,09	14	0,35	1560,00	2,50	1,44	8112,00	3,80	5	none	Carbon	312 : 1

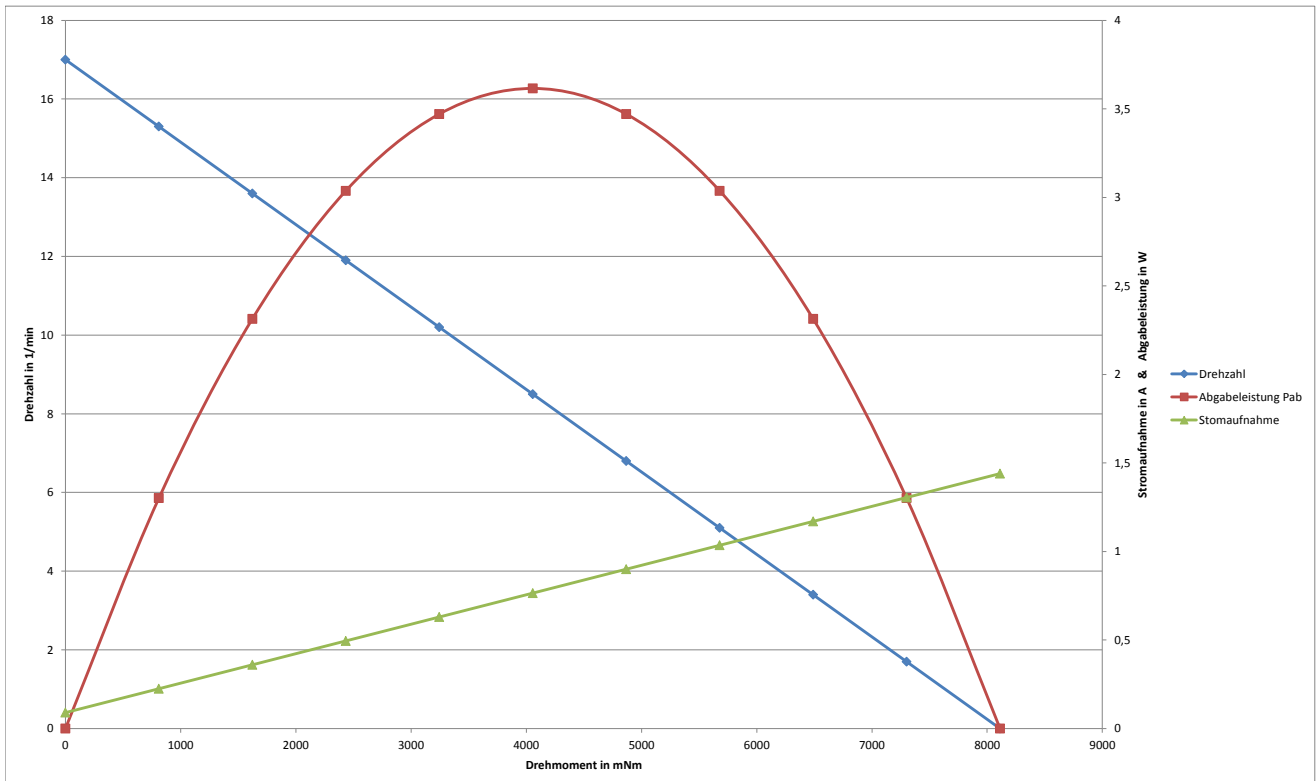

Irrtum und Druckfehler vorbehalten / Errors and Omissions excepted