
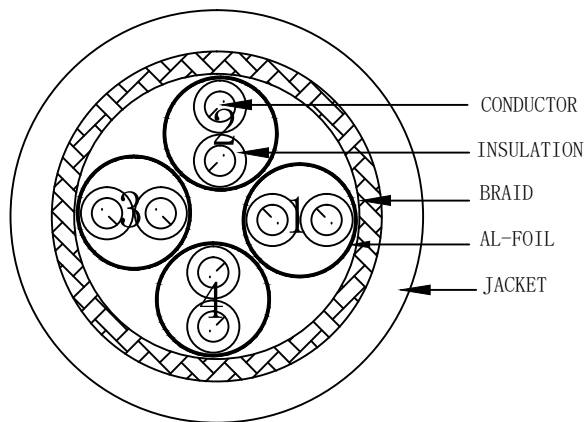


WIRING DIAGRAM

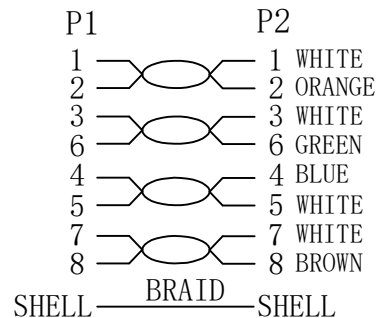

MATERIAL LIST

③	OVER MOLD	PVC(Color:SEE THE CHART)	2	
②	CONNECTOR	RJ45 8P8C Shielded Plug, Pin Gold Plated 3U", Shell Nickel plating Transparence red	2	
①	CABLE	S/FTP CAT. 6 (AWG27 BC+AL-FOIL)*4PAIRS +BRAID JACKET:PVC, OD:6.0±0.2mm	1	

NO.	PARTS NAME	SPECIFICATION STANDARD	QT' Y	REMARK
		NEW	2018-06-28	A
BY	CHK	REVISION RECORD MODIFICATION	DATE	REV.

NOTE:

- 100% OPEN SHORT, MISS WIRE TEST
- Fluke test :
TEST LIMIT:ISO 11801 Channel Class E
- PRINTING::CAT6 S/FTP 4x2x27AWG/7 PVC ISO11801 & EN50173 & ANSI/TIA568C.2
- ROHS2.0 AND REACH COMPLIANT
- Working temperature:-10°C ~ + 60°C
Storage temperature:-20°C~+75°C

CUSTOMER	CEI Conrad Electronic International(HK) Ltd	ITEM NO.	SEE THE CHART		
PRODUCT NAME	CAT.6 S/FTP 27AWG PVC	UNO ITEM NO.	216343	UNIT	MM
	DRAWN BY	CHECK BY	APPO BY	DATE	
	ARVIN	Alvan		2018-06-28	

CHART:

COLOR:GREY (RAL 7035)		
UNO ITEM NO.	LENGTH	packing
216343E, 01	150+40/-0mm	polybag+w/Renkforce sticker
216343E, 22	250+60/-0mm	polybag+w/Renkforce sticker
216343E, 50	500+60/-0mm	polybag+w/Renkforce sticker
216343E, 11	1000+60/-0mm	polybag+w/Renkforce sticker
216343E, 02	2000+100/-0mm	polybag+w/Renkforce sticker
216343E, 03	3000+100/-0mm	polybag+w/Renkforce sticker
216343E, 05	5000+100/-0mm	polybag+w/Renkforce sticker
216343E, 00	10000+100/-0mm	polybag+w/Renkforce sticker
216343E, 15	15000+100/-0mm	polybag+w/Renkforce sticker
216343E, 20	20000+100/-0mm	polybag+w/Renkforce sticker
216343E, 30	30000+100/-0mm	polybag+w/Renkforce sticker

COLOR:GREEN (Pantone 3278C)		
UNO ITEM NO.	LENGTH	packing
216343G, 01	150+40/-0mm	polybag+w/Renkforce sticker
216343G, 22	250+60/-0mm	polybag+w/Renkforce sticker
216343G, 50	500+60/-0mm	polybag+w/Renkforce sticker
216343G, 11	1000+60/-0mm	polybag+w/Renkforce sticker
216343G, 02	2000+100/-0mm	polybag+w/Renkforce sticker
216343G, 03	3000+100/-0mm	polybag+w/Renkforce sticker
216343G, 05	5000+100/-0mm	polybag+w/Renkforce sticker
216343G, 00	10000+100/-0mm	polybag+w/Renkforce sticker
216343G, 15	15000+100/-0mm	polybag+w/Renkforce sticker
216343G, 20	20000+100/-0mm	polybag+w/Renkforce sticker
216343G, 30	30000+100/-0mm	polybag+w/Renkforce sticker


COLOR:VIOLET (Pantone 2725C)		
UNO ITEM NO.	LENGTH	packing
216343P, 01	150+40/-0mm	polybag+w/Renkforce sticker
216343P, 22	250+60/-0mm	polybag+w/Renkforce sticker
216343P, 50	500+60/-0mm	polybag+w/Renkforce sticker
216343P, 11	1000+60/-0mm	polybag+w/Renkforce sticker
216343P, 02	2000+100/-0mm	polybag+w/Renkforce sticker
216343P, 03	3000+100/-0mm	polybag+w/Renkforce sticker
216343P, 05	5000+100/-0mm	polybag+w/Renkforce sticker
216343P, 00	10000+100/-0mm	polybag+w/Renkforce sticker
216343P, 15	15000+100/-0mm	polybag+w/Renkforce sticker
216343P, 20	20000+100/-0mm	polybag+w/Renkforce sticker
216343P, 30	30000+100/-0mm	polybag+w/Renkforce sticker

COLOR:BLACK (Pantone Black 3C)		
UNO ITEM NO.	LENGTH	packing
216343S, 01	150+40/-0mm	polybag+w/Renkforce sticker
216343S, 22	250+60/-0mm	polybag+w/Renkforce sticker
216343S, 50	500+60/-0mm	polybag+w/Renkforce sticker
216343S, 11	1000+60/-0mm	polybag+w/Renkforce sticker
216343S, 02	2000+100/-0mm	polybag+w/Renkforce sticker
216343S, 03	3000+100/-0mm	polybag+w/Renkforce sticker
216343S, 05	5000+100/-0mm	polybag+w/Renkforce sticker
216343S, 00	10000+100/-0mm	polybag+w/Renkforce sticker
216343S, 15	15000+100/-0mm	polybag+w/Renkforce sticker
216343S, 20	20000+100/-0mm	polybag+w/Renkforce sticker
216343S, 30	30000+100/-0mm	polybag+w/Renkforce sticker

COLOR:RED (Pantone 199C)		
UNO ITEM NO.	LENGTH	packing
216343R, 01	150+40/-0mm	polybag+w/Renkforce sticker
216343R, 22	250+60/-0mm	polybag+w/Renkforce sticker
216343R, 50	500+60/-0mm	polybag+w/Renkforce sticker
216343R, 11	1000+60/-0mm	polybag+w/Renkforce sticker
216343R, 02	2000+100/-0mm	polybag+w/Renkforce sticker
216343R, 03	3000+100/-0mm	polybag+w/Renkforce sticker
216343R, 05	5000+100/-0mm	polybag+w/Renkforce sticker
216343R, 00	10000+100/-0mm	polybag+w/Renkforce sticker
216343R, 15	15000+100/-0mm	polybag+w/Renkforce sticker
216343R, 20	20000+100/-0mm	polybag+w/Renkforce sticker
216343R, 30	30000+100/-0mm	polybag+w/Renkforce sticker

COLOR:BLUE (Pantone 647C)		
UNO ITEM NO.	LENGTH	packing
216343B, 01	150+40/-0mm	polybag+w/Renkforce sticker
216343B, 22	250+60/-0mm	polybag+w/Renkforce sticker
216343B, 50	500+60/-0mm	polybag+w/Renkforce sticker
216343B, 11	1000+60/-0mm	polybag+w/Renkforce sticker
216343B, 02	2000+100/-0mm	polybag+w/Renkforce sticker
216343B, 03	3000+100/-0mm	polybag+w/Renkforce sticker
216343B, 05	5000+100/-0mm	polybag+w/Renkforce sticker
216343B, 00	10000+100/-0mm	polybag+w/Renkforce sticker
216343B, 15	15000+100/-0mm	polybag+w/Renkforce sticker
216343B, 20	20000+100/-0mm	polybag+w/Renkforce sticker
216343B, 30	30000+100/-0mm	polybag+w/Renkforce sticker

COLOR:YELLOW (Pantone 135C)		
UNO ITEM NO.	LENGTH	packing
216343Y, 01	150+40/-0mm	polybag+w/Renkforce sticker
216343Y, 22	250+60/-0mm	polybag+w/Renkforce sticker
216343Y, 50	500+60/-0mm	polybag+w/Renkforce sticker
216343Y, 11	1000+60/-0mm	polybag+w/Renkforce sticker
216343Y, 02	2000+100/-0mm	polybag+w/Renkforce sticker
216343Y, 03	3000+100/-0mm	polybag+w/Renkforce sticker
216343Y, 05	5000+100/-0mm	polybag+w/Renkforce sticker
216343Y, 00	10000+100/-0mm	polybag+w/Renkforce sticker
216343Y, 15	15000+100/-0mm	polybag+w/Renkforce sticker
216343Y, 20	20000+100/-0mm	polybag+w/Renkforce sticker
216343Y, 30	30000+100/-0mm	polybag+w/Renkforce sticker

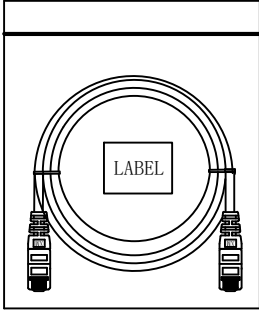

1pc/PE Bag+Renkforce sticker

CUSTOMER	CN	ITEM NO.	SEE THE CHART		
PRODUCT NAME	CAT. 6 S/FTP 27AWG PVC	UNO ITEM NO.	216343	UNIT	MM
2018-06-28	A	DRAWN BY	CHECK BY	APPO BY	DATE
DATE	REV.	ARVIN	Alvan		2018-06-28