




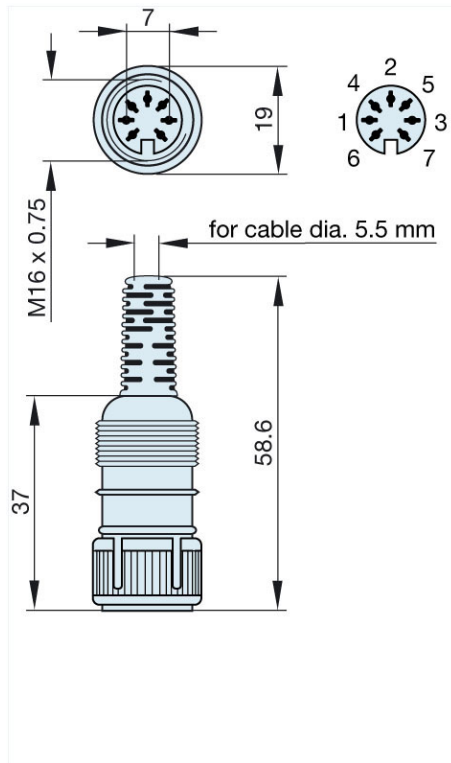
Product information MAK 7100 S grau/grey

Industrial Connecting Solutions: Circular Connectors: Audio/Video Connectors: DIN EN 60 130-09 Connectors (MAS/MAK series): with locking screw: Straight sockets: MAK 7100 S grau/grey

<http://www.e-catalog.beldensolutions.com/link/57078-24228-256281-256282-24384-24391-24396-34849/en/conf/uistate>

| | |
|--|---|
| Name | MAK 7100 S grau/grey |
| |  |
| | socket with locking screw; solder joint |
| Delivery informations | |
| Availability | available |
| Product description | |
| Type | MAK 7100 S grau/grey |
| Order No. | 930 682-517 |
| Type of contact | female |
| Description | socket with locking screw; solder joint |
| Housing Color | grey |
| Number of contacts | 7 |
| Conductor size | $\leq 0.34 \text{ mm}^2$ |
| Technical data | |
| LF output "Phone" | EN 60 130-09 |
| Pole arrangement DIN | DIN 45 329 |
| Rated current | 4 A |
| Rated voltage | AC/DC 34 V |
| Cable diameter | 5.5 mm |
| Type of termination | solder |
| Material | |
| Contact material (socket) | brass |
| Contact surface material | tin plated |
| Contact bearer material | PA 66/UL standard 94V-2 |
| Housing material | PE |
| Environmental conditions | |
| Protection class (IEC 60529) | IP 30 |
| Temperature range | -20 °C to +60 °C |
| Scope of delivery and accessories | |
| Packaging | retail package, polyethylene bag |

Picture
Drawing



Belden Deutschland GmbH
 Im Gewerbepark 2
 58579 Schalksmühle
 Germany
 Phone: +49 7127/14-1806
 E-Mail: icos-sales@belden.com

The information published in the websites has been compiled as carefully as possible. It is subject to alteration without notice in technical as well as in price-related/commercial respect. The complete information and data were available on user documentation. Mandatory information can only be obtained by a concrete query.