




## Product information GML 216 NJ LED 24 HH schwarz/black

Industrial Connecting Solutions:Rectangular Connectors:Valve Connectors (Type A -B -C):Type B:Field Attachable Valve Connectors:Valve Connectors with electronic insert (Industrial standard):GML 216

NJ LED 24 HH schwarz/black

<http://www.e-catalog.beldensolutions.com/link/57078-24228-256261-256266-256271-276218-24327-38202/en/conf/uistate>

<b>Name</b>	GML 216 NJ LED 24 HH schwarz/black
	
	function indicator (LED) with protective circuit (diode)
<b>Delivery informations</b>	
<b>Availability</b>	available
<b>Product description</b>	
<b>Description</b>	function indicator (LED) with protective circuit (diode)
<b>Type</b>	GML 216 NJ LED 24 HH schwarz/black
<b>Order No.</b>	934 458-002
<b>Other standard types</b>	transparent housing, cable gland grey; Order No. 934 460-003
<b>Number of contacts</b>	2 + PE
<b>Cable gland</b>	M 16 (black)
<b>Conductor size</b>	max. 1.5 mm <sup>2</sup>
<b>Standard</b>	industrial standard (11 mm)
<b>Housing Color</b>	transparent
<b>Construction type</b>	B
<b>Description of Wiring</b>	
<b>LED color</b>	LED red
<b>Suppressor</b>	diode
<b>Other characteristics</b>	correct polarity must be ensured
<b>Technical data</b>	
<b>Pin dimensions</b>	6.3 mm x 0.8 mm
<b>Rated voltage</b>	DC 24 V
<b>Rated current</b>	8 A
<b>Contact resistance</b>	<= 4 mOhm
<b>Type of termination</b>	screw / cable shoe / cable eye
<b>Suitable cables</b>	4.5 mm to 10 mm diameter
<b>Mounting</b>	central screw
<b>Material</b>	
<b>Contact surface material</b>	Sn
<b>Contact bearer material</b>	PA
<b>Housing material</b>	PA
<b>Environmental conditions</b>	
<b>Protection class (IEC 60529)</b>	IP 65
<b>Pollution severity</b>	3
<b>Temperature range</b>	-40 °C to +90 °C
<b>Inflammability class</b>	
<b>Housing</b>	94 V-1
<b>Contact bearer</b>	94 HB
<b>Approvals</b>	
<b>UR</b>	in preparation
<b>VDE</b>	in preparation
<b>Packaging unit</b>	
<b>Packaging unit</b>	50 pieces



# HIRSCHMANN

A BELDEN BRAND

Industrial Connecting Solutions:Rectangular Connectors:Valve Connectors (Type A -B -C):Type B:Field Attachable Valve Connectors:Valve Connectors with electronic insert (Industrial standard):GML 216

NJ LED 24 HH schwarz/black

<http://www.e-catalog.beldensolutions.com/link/57078-24228-256261-256266-256271-276218-24327-38202/en/conf/ui/state>


#### Scope of delivery and accessories

##### Accessories to order separately

(NBR) flat gasket GM 207-3, Order No. 731 423-002; knurled screw GDM 3011-8, Order No. 732 574-001; stainless steel screw GDM 3011 RF-1, Order No. 734 363-001

#### Picture

##### Drawing

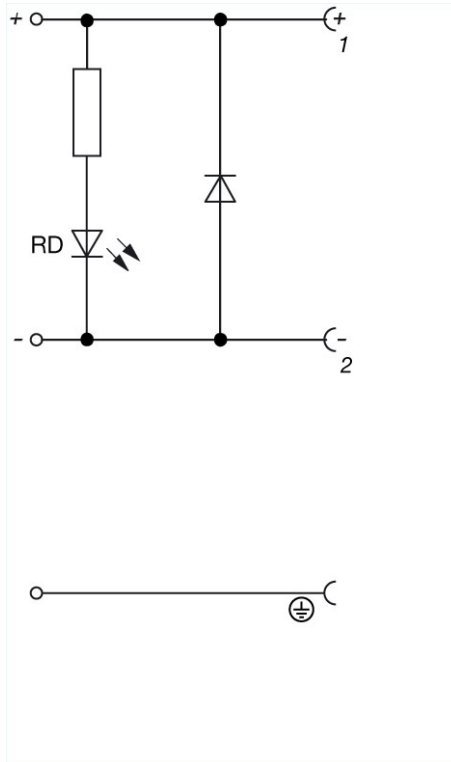

#### Belden Deutschland GmbH

Im Gewerbepark 2  
58579 Schalksmühle  
Germany  
Phone: +49 7127/14-1806  
E-Mail: [icos-sales@belden.com](mailto:icos-sales@belden.com)

The information published in the websites has been compiled as carefully as possible. It is subject to alteration without notice in technical as well as in price-related/commercial respect. The complete information and data were available on user documentation. Mandatory information can only be obtained by a concrete query.