




Product information GMNL 216 NJ LED 24 HH schwarz/black

Industrial Connecting Solutions:Rectangular Connectors:Valve Connectors (Type A -B -C):Type B:Field Attachable Valve Connectors:Valve Connectors with electronic insert (DIN EN 175 301-803):GMNL

216 NJ LED 24 HH schwarz/black

<http://www.e-catalog.beldensolutions.com/link/57078-24228-256261-256266-256271-276218-24322-38201/en/conf/uistate>

Name	GMNL 216 NJ LED 24 HH schwarz/black
	
	function indicator (LED) with protective circuit (diode)
Delivery informations	
Availability	available
Product description	
Description	function indicator (LED) with protective circuit (diode)
Type	GMNL 216 NJ LED 24 HH schwarz/black
Order No.	934 460-002
Other standard types	transparent housing, cable gland grey; Order No. 934 460-003
Number of contacts	2 + PE
Cable gland	M12 (black)
Cable diameter	6.5 mm
Conductor size	max. 1.5 mm ²
Standard	DIN EN 175 301-803-B
Housing Color	transparent
Construction type	B
Description of Wiring	
LED color	LED red
Suppressor	diode
Technical data	
Pin dimensions	6.3 mm x 0.8 mm
Rated voltage	DC 24 V
Rated current	8 A
Contact resistance	<= 4 mOhm
Type of termination	screw / cable shoe / cable eye
Suitable cables	4.5 mm to 10 mm diameter
Mounting	central screw
Material	
Contact surface material	Sn
Contact bearer material	PA
Housing material	PA
Environmental conditions	
Protection class (IEC 60529)	IP 65
Pollution severity	3
Temperature range	-40 °C to +90 °C
Inflammability class	
Housing	94 V-1
Contact bearer	94 HB
Approvals	
UR	in preparation
Packing unit	
Packaging unit	50 pieces



HIRSCHMANN

A BELDEN BRAND

Industrial Connecting Solutions:Rectangular Connectors:Valve Connectors (Type A -B -C):Type B:Field Attachable Valve Connectors:Valve Connectors with electronic insert (DIN EN 175 301-803):GMNL

216 NJ LED 24 HH schwarz/black

<http://www.e-catalog.beldensolutions.com/link/57078-24228-256261-256266-256271-276218-24322-38201/en/conf/ui/state>


Scope of delivery and accessories

Accessories to order separately

(NBR) flat gasket GMN 209-3, Order No. 733 273-002; knurled screw GDM 3011-8, Order No. 732 574-001; stainless steel screw GDM 3011 RF-1, Order No. 734 363-001

Picture

Drawing

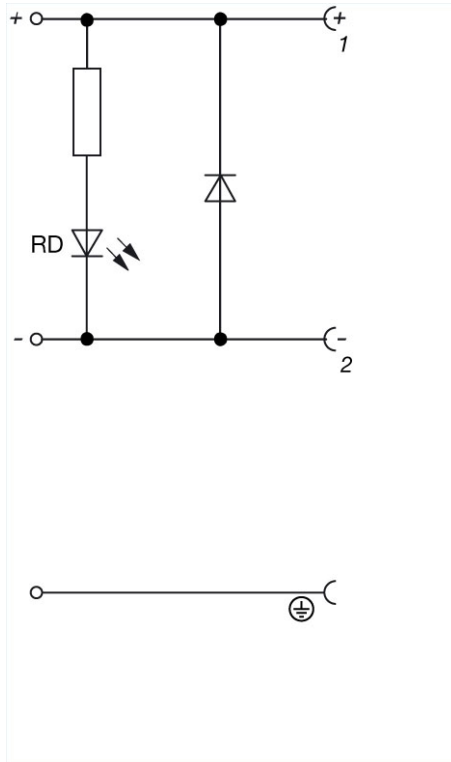

Belden Deutschland GmbH

Im Gewerbepark 2
58579 Schalksmühle
Germany
Phone: +49 7127/14-1806
E-Mail: icos-sales@belden.com

The information published in the websites has been compiled as carefully as possible. It is subject to alteration without notice in technical as well as in price-related/commercial respect. The complete information and data were available on user documentation. Mandatory information can only be obtained by a concrete query.