




## Product information G 30 KW 3 M 2m

Industrial Connecting Solutions:Rectangular Connectors:DIN VDE 0627 / IEC 61984 Connectors (G serie):Cable plug:G 30 KW 3 M 2m

<http://www.e-catalog.beldensolutions.com/link/57078-24228-256261-24347-24349-36964/en/conf/ui/state>

|  |   |
|--|---|
| Name                                     | G 30 KW 3 M 2m  |
|  |  |
|  | Cable plug with integrally molded lead  |
| <b>Delivery informations</b>             |   |
| Availability                             | available   |
| <b>Product description</b>               |   |
| Description                              | Cable plug with integrally molded lead  |
| Type                                     | G 30 KW 3 M 2m  |
| Order No.                                | 931 783-001   |
| Type of contact                          | blade contacts  |
| Number of contacts                       | 3 + PE  |
| Cable material                           | PVC   |
| Cable length                             | 2 m   |
| Conductor size                           | 4 x 0.75 mm <sup>2</sup>  |
| Cable type                               | A03 VV-F 4G0,75   |
| Standard                                 | DIN VDE 0627 / IEC 61984  |
| Housing Color                            | grey  |
| <b>Technical data</b>                    |   |
| Pin dimensions                           | 2.8 mm x 0.8 mm   |
| Rated voltage                            | AC/DC 250 V   |
| Rated current                            | 10 A  |
| Contact resistance                       | <= 4 mOhm   |
| Mounting                                 | central screw   |
| <b>Material</b>                          |   |
| Contact surface material                 | Sn  |
| Contact bearer material                  | PA  |
| Housing material                         | PA  |
| <b>Environmental conditions</b>          |   |
| Protection class (IEC 60529)             | IP 65   |
| Pollution severity                       | 3   |
| Temperature range                        | -40 °C to +90 °C  |
| <b>Inflammability class</b>              |   |
| Housing                                  | 94 HB   |
| Contact bearer                           | 94 HB   |
| <b>Approvals</b>                         |   |
| VDE                                      | VDE   |
| <b>Packing unit</b>                      |   |
| Packaging unit                           | 20 pieces   |
| <b>Scope of delivery and accessories</b> |   |
| Scope of delivery                        | 1 cable plug with integrally molded lead  |
| Accessories to order separately          | can be plugged into G 30 E 3 F grau/grey, G 30 W 3 F grau/grey, G 30 KW 3 F 2m    |



# HIRSCHMANN


A BELDEN BRAND

Industrial Connecting Solutions:Rectangular Connectors:DIN VDE 0627 / IEC 61984 Connectors (G serie):Cable plug:G 30 KW 3 M 2m

<http://www.e-catalog.beldensolutions.com/link/57078-24228-256261-24347-24349-36964/en/conf/ui/state>

Picture

Drawing

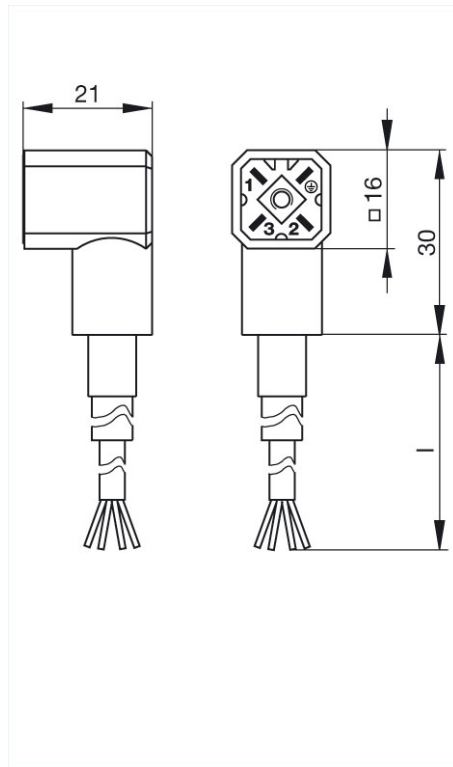

#### Belden Deutschland GmbH

Im Gewerbepark 2

58579 Schalksmühle

Germany

Phone: +49 7127/14-1806

E-Mail: [icos-sales@belden.com](mailto:icos-sales@belden.com)

The information published in the websites has been compiled as carefully as possible. It is subject to alteration without notice in technical as well as in price-related/commercial respect. The complete information and data were available on user documentation. Mandatory information can only be obtained by a concrete query.