

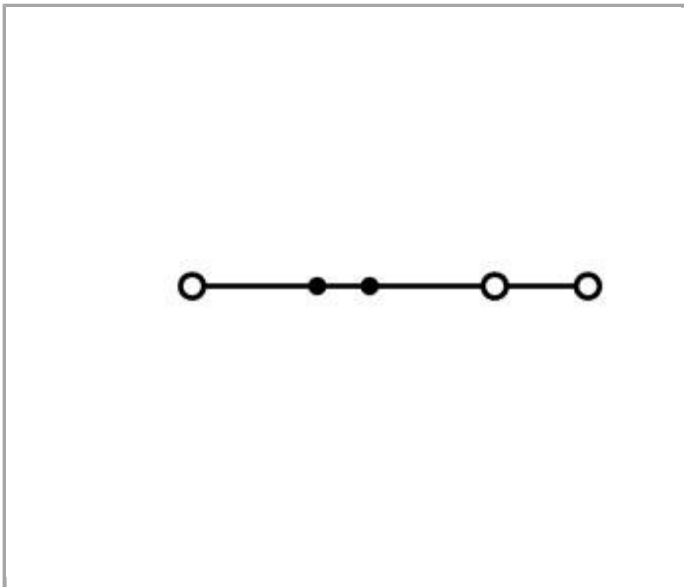


**Data sheet | Item number: 2204-1301**

3-conductor through terminal block; with push-button; 4 mm<sup>2</sup>; with test port; side and center marking; for DIN-rail 35 x 15 and 35 x 7.5; Push-in CAGE CLAMP®

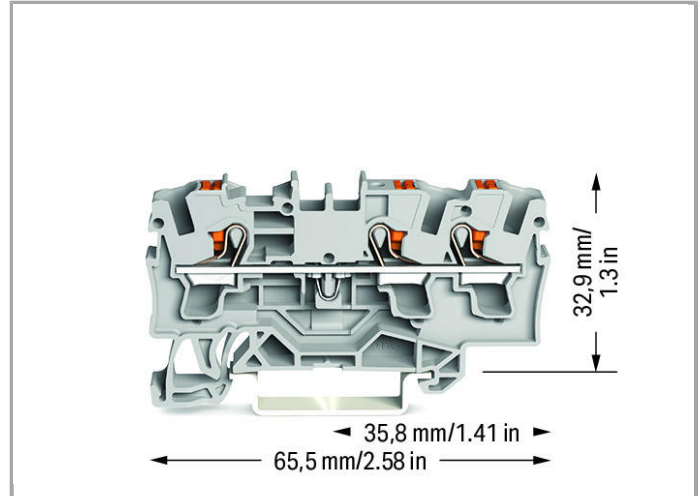

[www.wago.com/2204-1301](http://www.wago.com/2204-1301)

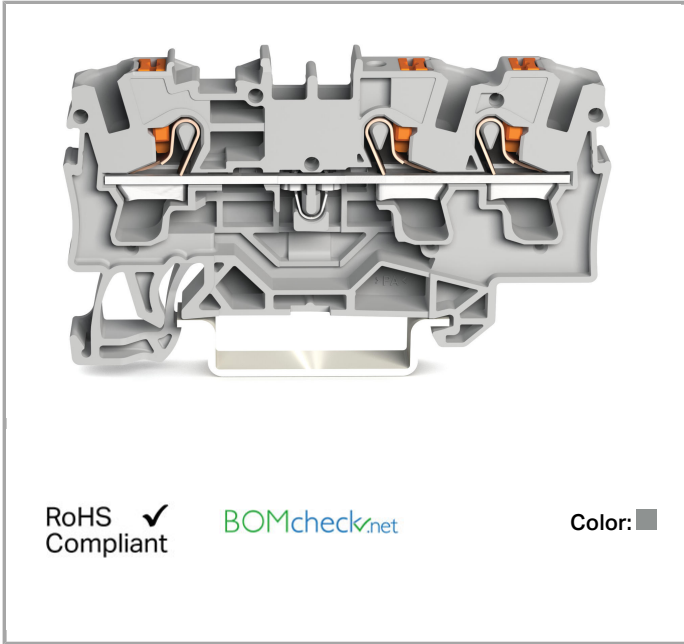

**Data**

**Electrical data**

**Ratings per IEC/EN 60664-1**

|                                 |       |
|---------------------------------|-------|
| Rated voltage (III / 3)         | 800 V |
| Rated impulse voltage (III / 3) | 8 kV  |



|                   |  |
|-------------------|--|
| Rated current     | 32 A   |
| Rated current (2) | 41 A   |
| Legend (ratings)  | (III / 3) $\triangleq$ Overvoltage category III / Pollution degree 3 |

### Approvals per UL 1059

|                                |       |
|--------------------------------|-------|
| Rated voltage UL (Use Group B) | 600 V |
| Rated current UL (Use Group B) | 30 A  |
| Rated voltage UL (Use Group C) | 600 V |
| Rated current UL (Use Group C) | 30 A  |

### Connection data

|   |   |
|---|---|
| Connection technology   | Push-in CAGE CLAMP <sup>®</sup>           |
| Actuation type  | Push-in<br>Push-button<br>Operating tool  |
| Connectable conductor materials                                 | Copper                                    |
| Nominal cross section   | 4 mm <sup>2</sup>                         |
| Solid conductor   | 0.5 ... 6 mm <sup>2</sup> / 20 ... 10 AWG |
| Solid conductor, push-in termination                            | 1 ... 6 mm <sup>2</sup> / 14 ... 10 AWG   |
| Fine-stranded conductor   | 0.5 ... 6 mm <sup>2</sup> / 20 ... 10 AWG |
| Fine-stranded conductor with ferrule, push-in termination, from | 0.75 mm <sup>2</sup> / 18 AWG             |
| Strip length  | 11 ... 13 mm / 0.43 ... 0.51 Inch         |
| Total number of connection points                               | 3   |
| Total number of potentials                                      | 1   |
| Number of levels  | 1   |
| Type of wiring  | Front-entry wiring                        |

### Geometrical Data

|                                       |                      |
|---------------------------------------|----------------------|
| Width                                 | 6.2 mm / 0.244 inch  |
| Height from upper-edge of DIN-35 rail | 32.9 mm / 1.295 inch |
| Depth                                 | 65.5 mm / 2.579 inch |

### Mechanical data

|                  |                     |
|------------------|---------------------|
| Design           | horizontal          |
| Type of mounting | DIN-35 rail         |
| Marking level    | Center/side marking |

### Material Data

|                     |                      |
|---------------------|----------------------|
| Color               | gray                 |
| Insulating material | Polyamide 66 (PA 66) |

|        |         |
|--------|---------|
| Weight | 9.161 g |
|--------|---------|

### Commercial data

|                    |               |
|--------------------|---------------|
| Packaging type     | BOX           |
| Country of origin  | DE            |
| GTIN               | 4055143711432 |
| Customs Tariff No. | 85369010000   |

### Approvals / Certificates

#### Ex-Approvals

| Logo | Approval | Certificate name |
|------|----------|------------------|
|------|----------|------------------|



|     |                                |
|-----|--------------------------------|
| AEx | Underwriters Laboratories Inc. |
|-----|--------------------------------|

|            |
|------------|
| 4788360975 |
|------------|



|       |                                       |
|-------|---------------------------------------|
| IECEX | Physikalisch Technische Bundesanstalt |
|-------|---------------------------------------|

|   |
|---|
| IECEX PTB 18.00 13U (Ex eb IIC Gb and Ex eb I Mb) |
|---|

#### Country specific Approvals

| Logo | Approval | Certificate name |
|------|----------|------------------|
|------|----------|------------------|



|     |                          |
|-----|--------------------------|
| CCA | DEKRA Certification B.V. |
|-----|--------------------------|

|             |
|-------------|
| NTR NL 7666 |
|-------------|



|           |                          |
|-----------|--------------------------|
| KEMA/KEUR | DEKRA Certification B.V. |
|-----------|--------------------------|

|           |
|-----------|
| 71-102877 |
|-----------|

#### UL-Approvals

| Logo | Approval | Certificate name |
|------|----------|------------------|
|------|----------|------------------|



|    |                                |
|----|--------------------------------|
| UL | Underwriters Laboratories Inc. |
|----|--------------------------------|

|            |
|------------|
| 4788360975 |
|------------|

### Compatible products

#### ferrule








 



 





















#### Item no.: 216-262

















Ferrule; Sleeve for 0.75 mm<sup>2</sup> / AWG 20; insulated; electro-tin plated; electrolytic copper; gastight crimped; acc. to DIN 46228, Part 4/09.90

[www.wago.com/216-262](http://www.wago.com/216-262)

#### Item no.: 216-263

|  |   |  |
|--|---|--|
|     | Ferrule; Sleeve for 1 mm <sup>2</sup> / AWG 18; insulated; electro-tin plated; electrolytic copper; gastight crimped; acc. to DIN 46228, Part 4/09.90                               | <a href="http://www.wago.com/216-263">www.wago.com/216-263</a>                   |
|     | <b>Item no.: 216-264</b><br>Ferrule; Sleeve for 1.5 mm <sup>2</sup> / AWG 16; insulated; electro-tin plated; electrolytic copper; gastight crimped; acc. to DIN 46228, Part 4/09.90 | <a href="http://www.wago.com/216-264">www.wago.com/216-264</a>                   |
|     | <b>Item no.: 216-266</b><br>Ferrule; Sleeve for 2.5 mm <sup>2</sup> / AWG 14; insulated; electro-tin plated; electrolytic copper; gastight crimped; acc. to DIN 46228, Part 4/09.90 | <a href="http://www.wago.com/216-266">www.wago.com/216-266</a>                   |
|     | <b>Item no.: 216-267</b><br>Ferrule; Sleeve for 4 mm <sup>2</sup> / AWG 12; insulated; electro-tin plated; electrolytic copper; gastight crimped; acc. to DIN 46228, Part 4/09.90   | <a href="http://www.wago.com/216-267">www.wago.com/216-267</a>                   |
| <b>Insulation stop</b>   |   |  |
|    | <b>Item no.: 2004-171</b><br>Insulation stop; 0.25 - 0.5 mm <sup>2</sup> ; 5 pieces/strip   | <a href="http://www.wago.com/2004-171">www.wago.com/2004-171</a>                 |
|    | <b>Item no.: 2004-172</b><br>Insulation stop; 0.75 - 1 mm <sup>2</sup> ; 5 pieces/strip   | <a href="http://www.wago.com/2004-172">www.wago.com/2004-172</a>                 |
| <b>Carrier rail</b>  |   |  |
|    | <b>Item no.: 210-112</b><br>Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; slotted; according to EN 60715; "Hole width 25 mm  | <a href="http://www.wago.com/210-112">www.wago.com/210-112</a>                   |
|  | <b>Item no.: 210-113</b><br>Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; unslotted; according to EN 60715   | <a href="http://www.wago.com/210-113">www.wago.com/210-113</a>                   |
|  | <b>Item no.: 210-114</b><br>Steel carrier rail; 35 x 15 mm; 1.5 mm thick; 2 m long; unslotted; similar to EN 60715  | <a href="http://www.wago.com/210-114">www.wago.com/210-114</a>                   |
|  | <b>Item no.: 210-115</b><br>Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; slotted; according to EN 60715; "Hole width 18 mm  | <a href="http://www.wago.com/210-115">www.wago.com/210-115</a>                   |
|  | <b>Item no.: 210-118</b><br>Steel carrier rail; 35 x 15 mm; 2.3 mm thick; 2 m long; unslotted; according to EN 60715  | <a href="http://www.wago.com/210-118">www.wago.com/210-118</a>                   |
|  | <b>Item no.: 210-196</b><br>Aluminum carrier rail; 35 x 8.2 mm; 1.6 mm thick; 2 m long; unslotted; similar to EN 60715  | <a href="http://www.wago.com/210-196">www.wago.com/210-196</a>                   |
|  | <b>Item no.: 210-197</b><br>Steel carrier rail; 35 x 15 mm; 1.5 mm thick; 2 m long; slotted; similar to EN 60715  | <a href="http://www.wago.com/210-197">www.wago.com/210-197</a>                   |
|  | <b>Item no.: 210-198</b><br>Copper carrier rail; 35 x 15 mm; 2.3 mm thick; 2 m long; unslotted; according to EN 60715   | <a href="http://www.wago.com/210-198">www.wago.com/210-198</a>                   |
| <b>Marking accessories</b>   |   |  |
|  | <b>Item no.: 2009-110</b><br>Marking strips; on reel; not stretchable; plain; snap-on type  | <a href="http://www.wago.com/2009-110">www.wago.com/2009-110</a>                 |
|  | <b>Item no.: 2009-115</b><br>WMB-Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type   | <a href="http://www.wago.com/2009-115">www.wago.com/2009-115</a>                 |
|  | <b>Item no.: 2009-115/000-002</b><br>WMB-Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type   | <a href="http://www.wago.com/2009-115/000-002">www.wago.com/2009-115/000-002</a> |

|  |  |  |
|--|--|--|
|    |  |  |
|    | <b>Item no.: 2009-115/000-006</b><br>WMB-Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type      | <a href="http://www.wago.com/2009-115/000-006">www.wago.com/2009-115/000-006</a> |
|    | <b>Item no.: 2009-115/000-007</b><br>WMB-Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type      | <a href="http://www.wago.com/2009-115/000-007">www.wago.com/2009-115/000-007</a> |
|    | <b>Item no.: 2009-115/000-012</b><br>WMB-Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type      | <a href="http://www.wago.com/2009-115/000-012">www.wago.com/2009-115/000-012</a> |
|    | <b>Item no.: 2009-115/000-017</b><br>WMB-Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type      | <a href="http://www.wago.com/2009-115/000-017">www.wago.com/2009-115/000-017</a> |
|    | <b>Item no.: 2009-115/000-023</b><br>WMB-Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type      | <a href="http://www.wago.com/2009-115/000-023">www.wago.com/2009-115/000-023</a> |
|    | <b>Item no.: 2009-115/000-024</b><br>WMB-Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type      | <a href="http://www.wago.com/2009-115/000-024">www.wago.com/2009-115/000-024</a> |
|  | <b>Item no.: 2009-135</b><br>WMB-Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type              | <a href="http://www.wago.com/2009-135">www.wago.com/2009-135</a>                 |
|  | <b>Item no.: 2009-145</b><br>Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type         | <a href="http://www.wago.com/2009-145">www.wago.com/2009-145</a>                 |
|  | <b>Item no.: 2009-145/000-002</b><br>Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type | <a href="http://www.wago.com/2009-145/000-002">www.wago.com/2009-145/000-002</a> |
|  | <b>Item no.: 2009-145/000-005</b><br>Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type | <a href="http://www.wago.com/2009-145/000-005">www.wago.com/2009-145/000-005</a> |
|  | <b>Item no.: 2009-145/000-006</b><br>Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type | <a href="http://www.wago.com/2009-145/000-006">www.wago.com/2009-145/000-006</a> |
|  | <b>Item no.: 2009-145/000-007</b><br>Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type | <a href="http://www.wago.com/2009-145/000-007">www.wago.com/2009-145/000-007</a> |
|  | <b>Item no.: 2009-145/000-012</b><br>Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type | <a href="http://www.wago.com/2009-145/000-012">www.wago.com/2009-145/000-012</a> |
|  | <b>Item no.: 2009-145/000-023</b><br>Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type | <a href="http://www.wago.com/2009-145/000-023">www.wago.com/2009-145/000-023</a> |

|  |   |  |
|--|---|--|
|    | <p><b>Item no.: 2009-145/000-024</b><br/>                 Mini-WSB Inline; on reel; stretchable 5 - 5.2 mm; plain; snap-on type</p>                   | <a href="http://www.wago.com/2009-145/000-024">www.wago.com/2009-145/000-024</a> |
|    | <p><b>Item no.: 2009-191</b><br/>                 Group marker carrier</p>  | <a href="http://www.wago.com/2009-191">www.wago.com/2009-191</a>                 |
|    | <p><b>Item no.: 2009-192</b><br/>                 Group marker carrier</p>  | <a href="http://www.wago.com/2009-192">www.wago.com/2009-192</a>                 |
|    | <p><b>Item no.: 2009-193</b><br/>                 Group marker carrier</p>  | <a href="http://www.wago.com/2009-193">www.wago.com/2009-193</a>                 |
|    | <p><b>Item no.: 2009-198</b><br/>                 Adaptor</p>   | <a href="http://www.wago.com/2009-198">www.wago.com/2009-198</a>                 |
|    | <p><b>Item no.: 248-501</b><br/>                 Miniature WSB Quick marking system; plain; Marker width 5 mm; 10 strips with 10 markers per card</p> | <a href="http://www.wago.com/248-501">www.wago.com/248-501</a>                   |
|    | <p><b>Item no.: 248-501/000-002</b><br/>                 Mini-WSB marking card; as card; not stretchable; plain; snap-on type</p>                     | <a href="http://www.wago.com/248-501/000-002">www.wago.com/248-501/000-002</a>   |
|    | <p><b>Item no.: 248-501/000-005</b><br/>                 Mini-WSB marking card; as card; plain; snap-on type</p>                                      | <a href="http://www.wago.com/248-501/000-005">www.wago.com/248-501/000-005</a>   |
|  | <p><b>Item no.: 248-501/000-006</b><br/>                 Mini-WSB marking card; as card; not stretchable; plain; snap-on type</p>                     | <a href="http://www.wago.com/248-501/000-006">www.wago.com/248-501/000-006</a>   |
|  | <p><b>Item no.: 248-501/000-007</b><br/>                 Mini-WSB marking card; as card; not stretchable; plain; snap-on type</p>                     | <a href="http://www.wago.com/248-501/000-007">www.wago.com/248-501/000-007</a>   |
|  | <p><b>Item no.: 248-501/000-012</b><br/>                 Mini-WSB marking card; as card; not stretchable; plain; snap-on type</p>                     | <a href="http://www.wago.com/248-501/000-012">www.wago.com/248-501/000-012</a>   |
|  | <p><b>Item no.: 248-501/000-017</b><br/>                 Mini-WSB marking card; as card; not stretchable; plain; snap-on type</p>                     | <a href="http://www.wago.com/248-501/000-017">www.wago.com/248-501/000-017</a>   |
|  | <p><b>Item no.: 248-501/000-023</b><br/>                 Mini-WSB marking card; as card; not stretchable; plain; snap-on type</p>                     | <a href="http://www.wago.com/248-501/000-023">www.wago.com/248-501/000-023</a>   |
|  | <p><b>Item no.: 248-501/000-024</b><br/>                 Mini-WSB marking card; as card; not stretchable; plain; snap-on type</p>                     | <a href="http://www.wago.com/248-501/000-024">www.wago.com/248-501/000-024</a>   |
|  | <p><b>Item no.: 793-501</b><br/>                 WMB marking card; as card; not stretchable; plain; snap-on type</p>                                  | <a href="http://www.wago.com/793-501">www.wago.com/793-501</a>                   |
|  | <p><b>Item no.: 793-501/000-002</b><br/>                 WMB marking card; as card; not stretchable; plain; snap-on type</p>                          | <a href="http://www.wago.com/793-501/000-002">www.wago.com/793-501/000-002</a>   |



**Item no.: 793-501/000-005**  
WMB marking card; as card; not stretchable; plain; snap-on type

[www.wago.com/793-501/000-005](http://www.wago.com/793-501/000-005)



**Item no.: 793-501/000-006**  
WMB marking card; as card; not stretchable; plain; snap-on type

[www.wago.com/793-501/000-006](http://www.wago.com/793-501/000-006)



**Item no.: 793-501/000-007**  
WMB marking card; as card; not stretchable; plain; snap-on type

[www.wago.com/793-501/000-007](http://www.wago.com/793-501/000-007)



**Item no.: 793-501/000-012**  
WMB marking card; as card; not stretchable; plain; snap-on type

[www.wago.com/793-501/000-012](http://www.wago.com/793-501/000-012)



**Item no.: 793-501/000-017**  
WMB marking card; as card; not stretchable; plain; snap-on type

[www.wago.com/793-501/000-017](http://www.wago.com/793-501/000-017)



**Item no.: 793-501/000-023**  
WMB marking card; as card; not stretchable; plain; snap-on type

[www.wago.com/793-501/000-023](http://www.wago.com/793-501/000-023)



**Item no.: 793-501/000-024**  
WMB marking card; as card; not stretchable; plain; snap-on type

[www.wago.com/793-501/000-024](http://www.wago.com/793-501/000-024)



**Item no.: 793-5501**  
WMB marking card; as card; for terminal block width 5 - 17.5 mm; stretchable 5 - 5.2 mm; plain; snap-on type

[www.wago.com/793-5501](http://www.wago.com/793-5501)



**Item no.: 793-5501/000-002**  
WMB marking card; as card; for terminal block width 5 - 17.5 mm; stretchable 5 - 5.2 mm; plain; snap-on type

[www.wago.com/793-5501/000-002](http://www.wago.com/793-5501/000-002)



**Item no.: 793-5501/000-005**  
WMB marking card; as card; stretchable 5 - 5.2 mm; plain; snap-on type

[www.wago.com/793-5501/000-005](http://www.wago.com/793-5501/000-005)



**Item no.: 793-5501/000-006**  
WMB marking card; as card; stretchable 5 - 5.2 mm; plain; snap-on type

[www.wago.com/793-5501/000-006](http://www.wago.com/793-5501/000-006)



**Item no.: 793-5501/000-007**  
WMB marking card; as card; stretchable 5 - 5.2 mm; plain; snap-on type

[www.wago.com/793-5501/000-007](http://www.wago.com/793-5501/000-007)



**Item no.: 793-5501/000-012**  
WMB marking card; as card; stretchable 5 - 5.2 mm; plain; snap-on type

[www.wago.com/793-5501/000-012](http://www.wago.com/793-5501/000-012)



**Item no.: 793-5501/000-017**  
WMB marking card; as card; stretchable 5 - 5.2 mm; plain; snap-on type

[www.wago.com/793-5501/000-017](http://www.wago.com/793-5501/000-017)



**Item no.: 793-5501/000-023**  
WMB marking card; as card; stretchable 5 - 5.2 mm; plain; snap-on type

[www.wago.com/793-5501/000-023](http://www.wago.com/793-5501/000-023)



**Item no.: 793-5501/000-024**  
WMB marking card; as card; stretchable 5 - 5.2 mm; plain; snap-on type

[www.wago.com/793-5501/000-024](http://www.wago.com/793-5501/000-024)

### End plate



**Item no.: 2004-1391**  
End and intermediate plate; 1 mm thick

[www.wago.com/2004-1391](http://www.wago.com/2004-1391)



**Item no.: 2004-1392**  
End and intermediate plate; 1 mm thick

[www.wago.com/2004-1392](http://www.wago.com/2004-1392)



**Item no.: 2004-1393**  
Separator plate; 2 mm thick; oversized

[www.wago.com/2004-1393](http://www.wago.com/2004-1393)



**Item no.: 2004-1394**  
Separator plate; 2 mm thick; oversized

[www.wago.com/2004-1394](http://www.wago.com/2004-1394)

### check



**Item no.: 2004-511**  
Modular TOPJOB®S connector; modular; for jumper contact slot; 1-pole

[www.wago.com/2004-511](http://www.wago.com/2004-511)



**Item no.: 2004-549**  
Spacer module; modular; e.g., for bridging commoned terminal blocks

[www.wago.com/2004-549](http://www.wago.com/2004-549)



**Item no.: 2004-552**  
TOPJOB®S connector strip; for jumper contact slot; 2-pole

[www.wago.com/2004-552](http://www.wago.com/2004-552)



**Item no.: 2004-553**  
TOPJOB®S connector strip; for jumper contact slot; 3-pole

[www.wago.com/2004-553](http://www.wago.com/2004-553)



**Item no.: 2004-554**  
TOPJOB®S connector strip; for jumper contact slot; 4-pole

[www.wago.com/2004-554](http://www.wago.com/2004-554)



**Item no.: 2004-555**  
TOPJOB®S connector strip; for jumper contact slot; 5-pole

[www.wago.com/2004-555](http://www.wago.com/2004-555)



**Item no.: 2009-174**  
Test plug adapter; for 4 mm Ø test plugs; for testing TOPJOB®S rail-mounted terminal blocks

[www.wago.com/2009-174](http://www.wago.com/2009-174)



**Item no.: 2009-182**  
Testing tap; for max. 2.5 mm<sup>2</sup>; tool-free connection for individual test wires 0.08 - 2.5 mm

[www.wago.com/2009-182](http://www.wago.com/2009-182)

### Jumper



**Item no.: 2004-402**  
Push-in type jumper bar; insulated; 2-way; Nominal current 32 A

[www.wago.com/2004-402](http://www.wago.com/2004-402)



**Item no.: 2004-403**  
Push-in type jumper bar; insulated; 3-way; Nominal current 32 A

[www.wago.com/2004-403](http://www.wago.com/2004-403)



**Item no.: 2004-404**  
Push-in type jumper bar; insulated; 4-way; Nominal current 32 A
















 
 


[www.wago.com/2004-404](http://www.wago.com/2004-404)



**Item no.: 2004-405**  
Push-in type jumper bar; insulated; 5-way; Nominal current 32 A

[www.wago.com/2004-405](http://www.wago.com/2004-405)



|  |  |  |
|--|--|--|
|    | <b>Item no.: 2004-405/011-000</b><br>Star point jumper; insulated; 3-way (1-3-5); IN = IN terminal block                               | <a href="http://www.wago.com/2004-405/011-000">www.wago.com/2004-405/011-000</a> |
|    | <b>Item no.: 2004-406</b><br>Push-in type jumper bar; insulated; 6-way; Nominal current 32 A   | <a href="http://www.wago.com/2004-406">www.wago.com/2004-406</a>                 |
|    | <b>Item no.: 2004-406/020-000</b><br>Delta jumper; insulated; 1-2 3-4 5-6; IN = IN terminal block                                      | <a href="http://www.wago.com/2004-406/020-000">www.wago.com/2004-406/020-000</a> |
|    | <b>Item no.: 2004-407</b><br>Push-in type jumper bar; insulated; 7-way; Nominal current 32 A   | <a href="http://www.wago.com/2004-407">www.wago.com/2004-407</a>                 |
|    | <b>Item no.: 2004-408</b><br>Push-in type jumper bar; insulated; 8-way; Nominal current 32 A   | <a href="http://www.wago.com/2004-408">www.wago.com/2004-408</a>                 |
|    | <b>Item no.: 2004-409</b><br>Push-in type jumper bar; insulated; 9-way; Nominal current 32 A   | <a href="http://www.wago.com/2004-409">www.wago.com/2004-409</a>                 |
|    | <b>Item no.: 2004-410</b><br>Push-in type jumper bar; insulated; 10-way; Nominal current 32 A  | <a href="http://www.wago.com/2004-410">www.wago.com/2004-410</a>                 |
|    | <b>Item no.: 2004-433</b><br>Push-in type jumper bar; insulated; from 1 to 3; Nominal current 32 A                                     | <a href="http://www.wago.com/2004-433">www.wago.com/2004-433</a>                 |
|  | <b>Item no.: 2004-434</b><br>Push-in type jumper bar; insulated; from 1 to 4; Nominal current 32 A                                     | <a href="http://www.wago.com/2004-434">www.wago.com/2004-434</a>                 |
|  | <b>Item no.: 2004-435</b><br>Push-in type jumper bar; insulated; from 1 to 5; Nominal current 32 A                                     | <a href="http://www.wago.com/2004-435">www.wago.com/2004-435</a>                 |
|  | <b>Item no.: 2004-436</b><br>Push-in type jumper bar; insulated; from 1 to 6; Nominal current 32 A                                     | <a href="http://www.wago.com/2004-436">www.wago.com/2004-436</a>                 |
|  | <b>Item no.: 2004-437</b><br>Push-in type jumper bar; insulated; from 1 to 7; Nominal current 32 A                                     | <a href="http://www.wago.com/2004-437">www.wago.com/2004-437</a>                 |
|  | <b>Item no.: 2004-438</b><br>Push-in type jumper bar; insulated; from 1 to 8; Nominal current 32 A                                     | <a href="http://www.wago.com/2004-438">www.wago.com/2004-438</a>                 |
|  | <b>Item no.: 2004-439</b><br>Push-in type jumper bar; insulated; from 1 to 9; Nominal current 32 A                                     | <a href="http://www.wago.com/2004-439">www.wago.com/2004-439</a>                 |
|  | <b>Item no.: 2004-440</b><br>Push-in type jumper bar; insulated; from 1 to 10; Nominal current 32 A                                    | <a href="http://www.wago.com/2004-440">www.wago.com/2004-440</a>                 |
|  | <b>Item no.: 2006-499</b><br>Step-down jumper; insulated; from 6/4 mm <sup>2</sup> to 4/2.5/1.5 mm <sup>2</sup> ; Nominal current 32 A | <a href="http://www.wago.com/2006-499">www.wago.com/2006-499</a>                 |
|  | <b>Item no.: 210-103</b><br>Wire commoning chain; insulated; 50 connections  | <a href="http://www.wago.com/210-103">www.wago.com/210-103</a>                   |
|  | <b>Item no.: 210-123</b><br>Wire commoning chain; insulated; 50 connections  | <a href="http://www.wago.com/210-123">www.wago.com/210-123</a>                   |
| <b>tools</b>   |  |  |
|  | <b>Item no.: 210-658</b><br>Operating tool with partially insulated shaft; Blade (3.5 x 0.5) mm; short; angled                         | <a href="http://www.wago.com/210-658">www.wago.com/210-658</a>                   |



Item no.: 210-720

Operating tool with partially insulated shaft; Type 2, blade (3.5 x 0.5) mm

[www.wago.com/210-720](http://www.wago.com/210-720)

## Downloads

### Documentation

#### Bid Text

|           |              |                 |          |
|-----------|--------------|-----------------|----------|
| 2204-1301 | Aug 15, 2018 | DOCX<br>15.2 kB | Download |
|-----------|--------------|-----------------|----------|

## smartDATA

### CAD data

|                       |     |          |
|-----------------------|-----|----------|
| 3D Download 2204-1301 | URL | Download |
|-----------------------|-----|----------|

Subject to changes.