

SENTRON, cylindrical fuse holder, 22x58 mm, 1-pole, In: 100 A, Un AC: 690 V



Model	
Product brand name	SENTRON
Product designation	Cylindrical fuse holder
General technical data	
Number of poles	1
Size of fuse link	22 x 58 mm
Supply voltage	
Current / at AC / rated value	100 A
Operating voltage	690 V
• at AC / rated value	
Protection class IP	IP20
Mechanical Design	
Height	117 mm
Width	36 mm
Depth	70 mm
Net weight	154 g
Certificates	

Reference code

- acc. to DIN EN 61346-2
- acc. to DIN EN 81346-2

F  
F

Declaration of Conformity

Test Certificates



EG-Konf.

[Miscellaneous](#)

Further information

**Information- and Downloadcenter (Catalogs, Brochures,...)**

<http://www.siemens.com/lowvoltage/catalogs>

**Industry Mall (Online ordering system)**

<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=3NW7211>

**Service&Support (Manuals, Certificates, Characteristics, FAQs,...)**

<https://support.industry.siemens.com/cs/ww/en/ps/3NW7211>

**Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)**


[http://www.automation.siemens.com/bilddb/cax\\_en.aspx?mlfb=3NW7211](http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=3NW7211)

**CAX-Online-Generator**

<http://www.siemens.com/cax>

**Tender specifications**

<http://www.siemens.com/specifications>

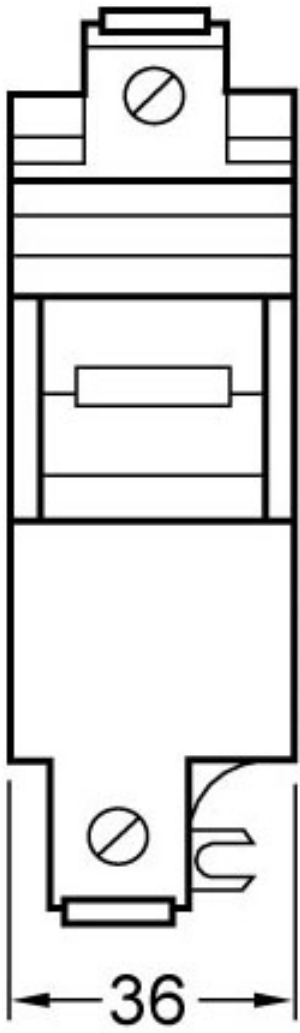

I2Y1\_00183

