

Data sheet for Line reactor

MLFB-Ordering data

6SE6400-3CC11-2FD0

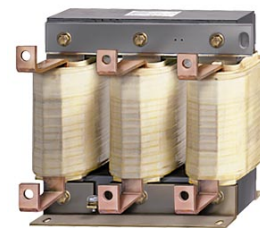


Figure similar

Client order no. :

Order no. :

Offer no. :

Remarks :

Item no. :

Consignment no. :

Project :

Rated data		Connections	
Input		Line side	
Number of phases	3 AC	Version	Flange connection for cable lug M10
Line voltage	380 ... 600 V		
Output		Load side	
Rated current	151.0 A	Version	Flange connection for cable lug M10
Mechanical data		PE connection	
Dimensions		Version	M8 screw studs
Width	240.0 mm (9.4 in)	Standards	
Height	228.0 mm (9.0 in)	Compliance with standards	cURus
Depth	141.0 mm (5.5 in)		
Degree of protection	IP20 / UL open type		
Net weight	25.0 kg (55.1 lb)		