

MLFB-Ordering data

6SE6400-3TC07-5ED0

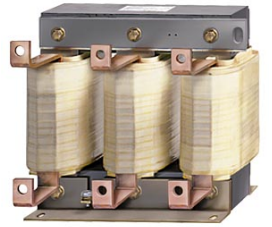


Figure similar

Client order no. :

Order no. :

Offer no. :

Remarks :

Item no. :

Consignment no. :

Project :

Rated data		Connections	
Rated voltage	380.00 ... 480.00 V	Power connection Power Module	
Rated current	90.00 A	Version	flat connector for cable lug M6
Power loss	0.277 kW	Power connection motor	
Mechanical data		Version	Flange connection for cable lug M6
Width	270.0 mm (10.63 in)	Max. motor cable length	
Height	248.0 mm (9.76 in)	3 AC 380 V -10 % ... 400 V	
Depth	188.0 mm (7.40 in)	Shielded	200 m
Degree of protection	IP00	Unshielded	300 m
Net weight	26.70 kg (58.86 lb)	3 AC 401 V ... 480 V +10 %	
		Shielded	200 m
		Unshielded	300 m
		PE connection	
		Version	M6 screw