

MLFB-Ordering data

6SE6400-3TC14-5FD0

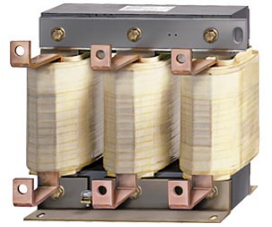


Figure similar

Client order no. :

Order no. :

Offer no. :

Remarks :

Item no. :

Consignment no. :

Project :

Rated data		Connections	
Rated voltage	380.00 ... 480.00 V	Power connection Power Module	
Rated current	178.00 A	Version	flat connector for cable lug M8
Power loss	0.469 kW	Power connection motor	
Mechanical data		Version	Flange connection for cable lug M8
Width	357.0 mm (14.06 in)	Max. motor cable length	
Height	321.0 mm (12.64 in)	3 AC 380 V -10 % ... 400 V	
Depth	221.0 mm (8.70 in)	Shielded	200 m
Degree of protection	IP00	Unshielded	300 m
Net weight	56.80 kg (125.22 lb)	3 AC 401 V ... 480 V +10 %	
		Shielded	200 m
		Unshielded	300 m
		PE connection	
		Version	M8 Screw