

SENTRON, fuse holder, Class CC, 2-pole, In: 30 A, Un AC: 600 V, respect national installation rules!



Model	
Product brand name	SENTRON
Product designation	Fuse holder
General technical data	
Number of poles	2
Size of fuse link	Class CC
Supply voltage	
Current / at AC / rated value	30 A
Operating voltage	
• at AC / rated value	600 V
Protection class IP	IP20
Mechanical Design	
Height	85 mm
Width	36 mm
Depth	65 mm
Net weight	105 g
Certificates	

#### Reference code

- acc. to DIN EN 61346-2
- acc. to DIN EN 81346-2

F

F

#### General Product Approval

#### Declaration of Conformity



#### Further information

##### Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/lowvoltage/catalogs>

##### Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=3NW7523-0HG>

##### Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/3NW7523-0HG>

##### Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)


[http://www.automation.siemens.com/bilddb/cax\\_en.aspx?mlfb=3NW7523-0HG](http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=3NW7523-0HG)

##### CAX-Online-Generator

<http://www.siemens.com/cax>

##### Tender specifications

<http://www.siemens.com/specifications>

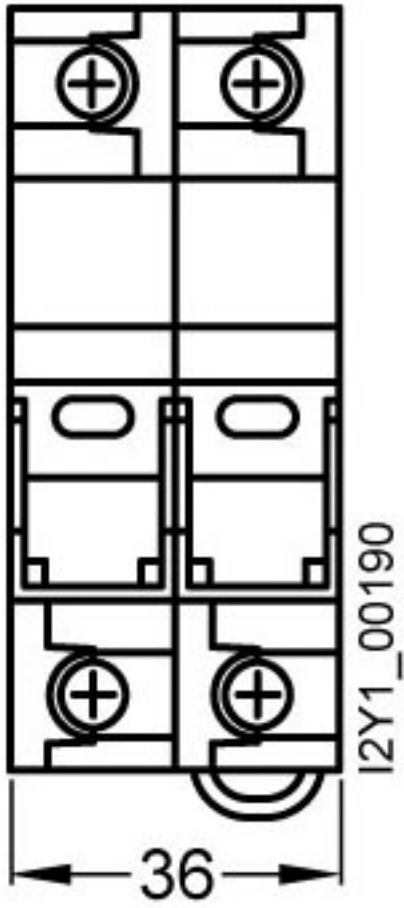

I2Y1\_00190

