

Data sheet for Line reactor

MLFB-Ordering data

6SE6400-3CC11-7FD0

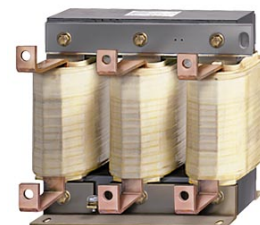


Figure similar

Client order no. :

Order no. :

Offer no. :

Remarks :

Item no. :

Consignment no. :

Project :

Rated data		Connections	
Input		Line side	
Number of phases	3 AC	Version	Flange connection for cable lug M10
Line voltage	200 ... 480 V		
Output		Load side	
Rated current	186.0 A	Version	Flange connection for cable lug M10
Mechanical data		PE connection	
Dimensions		Version	
Width	240.0 mm (9.4 in)	M8 screw studs	
Height	228.0 mm (9.0 in)	Standards	
Depth	141.0 mm (5.5 in)	Compliance with standards	
Degree of protection	IP20 / UL open type	cURus	
Net weight	24.0 kg (52.9 lb)		