

MLFB-Ordering data

6SE6400-3TC15-4FD0

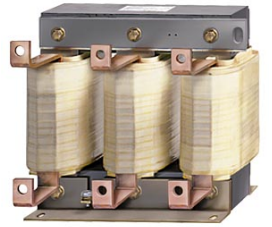


Figure similar

Client order no. :

Order no. :

Offer no. :

Remarks :

Item no. :

Consignment no. :

Project :

Rated data		Connections	
Rated voltage	200.00 ... 480.00 V	<b>Power connection Power Module</b>	
Rated current	178.00 A	Version	flat connector for cable lug M8
Power loss	0.245 kW	<b>Power connection motor</b>	
<b>Mechanical data</b>		Version	Flange connection for cable lug M8
Width	270.0 mm (10.63 in)	<b>Max. motor cable length</b>	
Height	248.0 mm (9.76 in)	3 AC 380 V -10 % ... 400 V	
Depth	188.0 mm (7.40 in)	Shielded	200 m
Degree of protection	IP00	Unshielded	300 m
Net weight	24.00 kg (52.91 lb)	3 AC 401 V ... 480 V +10 %	
		Shielded	200 m
		Unshielded	300 m
		<b>PE connection</b>	
		Version	M6 screw