

MLFB-Ordering data

6SE6400-3TC08-0ED0

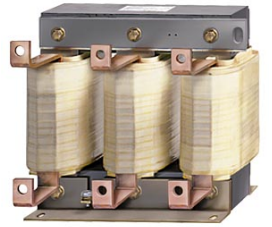


Figure similar

Client order no. :

Order no. :

Offer no. :

Remarks :

Item no. :

Consignment no. :

Project :

Rated data		Connections	
Rated voltage	200.00 ... 480.00 V	Power connection Power Module	
Rated current	104.00 A	Version	flat connector for cable lug M6
Power loss	0.170 kW	Power connection motor	
Mechanical data		Version	Flange connection for cable lug M6
Width	225.0 mm (8.86 in)	Max. motor cable length	
Height	210.0 mm (8.27 in)	3 AC 380 V -10 % ... 400 V	
Depth	140.0 mm (5.51 in)	Shielded	200 m
Degree of protection	IP00	Unshielded	300 m
Net weight	12.10 kg (26.68 lb)	3 AC 401 V ... 480 V +10 %	
		Shielded	200 m
		Unshielded	300 m
		PE connection	
		Version	M6 screw