
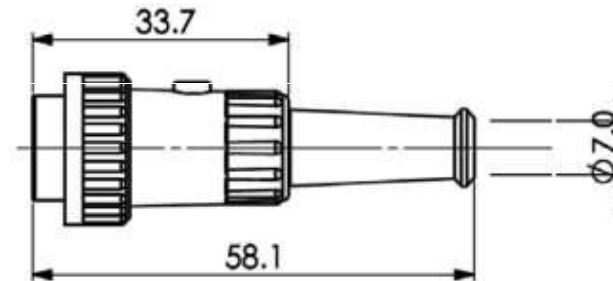
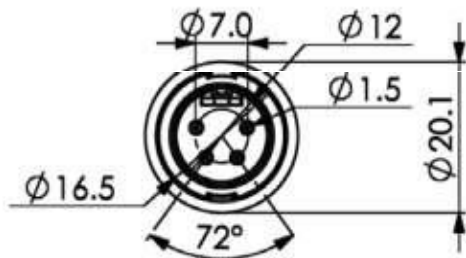


# Datenblatt

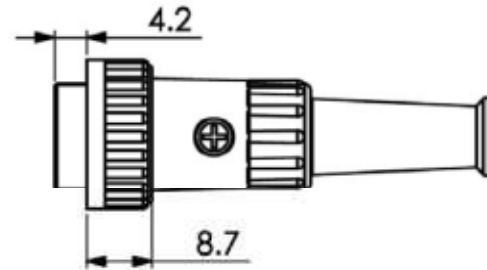

7	Strain Boot	PVC		1
6	Terminals	Brass	Silver Ptd.	4
5	4P Housing	PA66		1
4	Setscrew	Steel	Nickel Ptd.	1
3	T Holder	Steel	Nickel Ptd.	1
2	YE-139X Cap	Zn Alloy	Nickel Ptd.	1
1	YE-139X Cover	Zn Alloy	Nickel Ptd.	1
No.	Description	Material	Treat	Q'ty

### Specifications

#### rating :

100V AC 1A MAX

#### contact resistance :

pins-30mΩ MAX; shell-50mΩ MAX

#### insulation resistance :

MIN 100 MEGΩ @500V DC

#### voltage withstand :

250V AC R.M.S. for 1 minute

RoHS COMPLIANT

TITLE: 4P DIN CABLE PLUG BAYONT LOCKING TYPE