
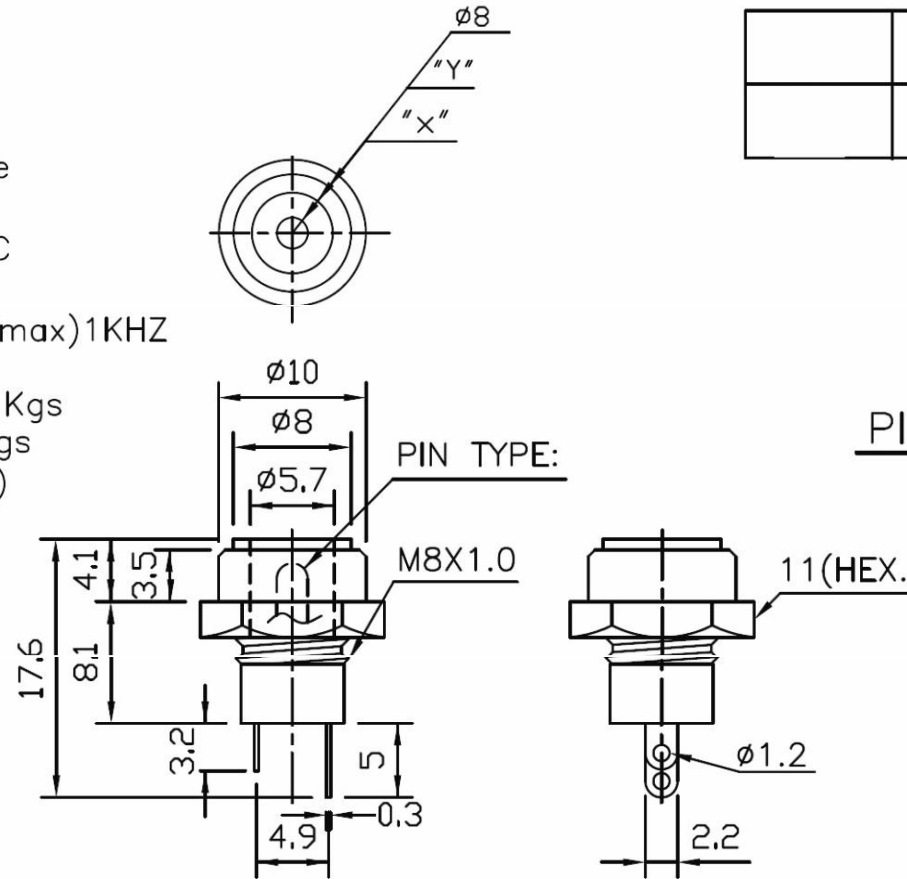


Datenblatt

Specification

1. Rating : 5A 12VDC
2. Withstanding voltage
AC 500V , 60Hz for 1 minute
3. Insulation resistance(initial)
100M ohm(min.) at 500 V DC
4. Contact resistance(initial)
30m ohm max.at AC 100mA(max)1KHZ
5. Insertion & Extraction force
Initial : 0.3 to 3.0 Kgs
After life test : 0.2 to 3.0 Kgs
6. Life test(20-30 cycle/minute)
5,000 cycles unloading

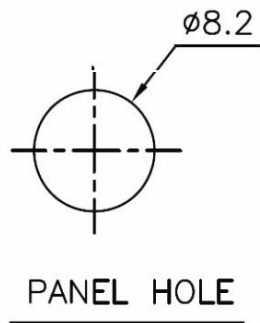

	"X"	"Y"
	∅2.5	∅5.5

PIN TYPE