



Datenblatt

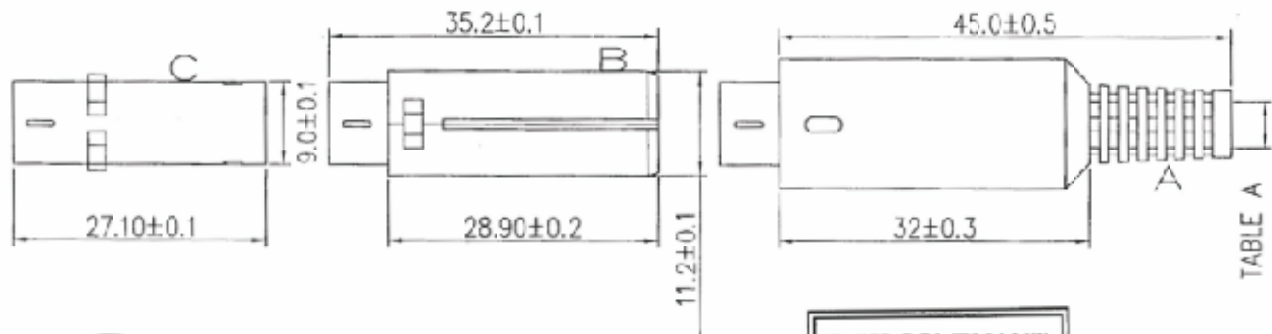

RoHS COMPLIANT

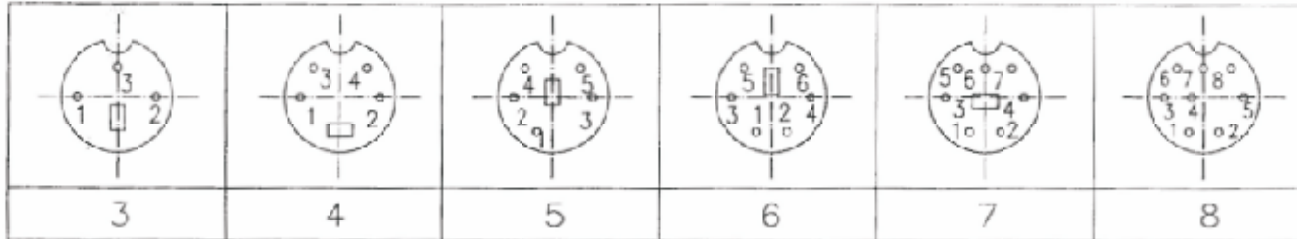

SPECIFICATIONS:

1. RATING: 11V AC 1A MAX
OR 12V DC 2A MAX.
2. INSULATION RESISTANCE:
50M OHM MIN AT 500V DC.
3. DIELECTRIC STRENGTH:
500V AC / 1 MINUTE.

<input type="checkbox"/>	7.0φ BACK SHELL
<input type="checkbox"/>	6.0φ BACK SHELL
<input checked="" type="checkbox"/>	5.0φ BACK SHELL (STANDARD)
<input type="checkbox"/>	COVER DIM

TABLE A

MATERIAL:

- A COVER: PE+2L
- B SHELL: ABS
- C METAL SHIELD:
BRASS NICKEL PLATED
- D HOUSING: NYLON66+CF
- E CONTACT:
BRASS SILVER PLATED